

# IT CABLING BY RENKFORCE

Office Workplace Solutions



## PC MONITOR CABLES

Computers forward graphics data to monitors using a range of different ports, connectors and cables. However, many monitor cables are unidirectional (i.e. are limited to sending data from a laptop to an external screen).

To find the monitor cable you need, you first need to check the respective port on your laptop, PC, or docking station. So-called bidirectional cables work both ways.



### MONITOR CABLES

Product ID	Laptop connector	Monitor connector	Bidirectional	Resolution	Copper	FO/ copper hybrid	Length
1409674-NW	DisplayPort	DisplayPort	x	4K @ 60Hz	x	-	0.50 m
1716996-NW	DisplayPort	DisplayPort	x	4K @ 60Hz	x	-	1.00 m
1404067-NW	DisplayPort	DisplayPort	x	4K @ 60Hz	x	-	1.80 m
1404068-NW	DisplayPort	DisplayPort	x	4K @ 60Hz	x	-	3.00 m
1404069-NW	DisplayPort	DisplayPort	x	4K @ 60Hz	x	-	4.50 m
1716997-NW	DisplayPort	DisplayPort	x	4K @ 60Hz	x	-	7.50 m
1716998-NW	DisplayPort	DisplayPort	x	4K @ 60Hz	x	-	10.00 m
2299009-NW	DisplayPort	DisplayPort	-	8K @ 60Hz 4K @ 120Hz	-	x	15 m
2299008-NW	DisplayPort	DisplayPort	-	8K @ 60Hz 4K @ 120Hz	-	x	20 m
2299007-NW	DisplayPort	DisplayPort	-	8K @ 60Hz 4K @ 120Hz	-	x	30 m
2299006-NW	DisplayPort	DisplayPort	-	4K @ 30Hz	-	x	50 m
2589593-NW	DisplayPort	HDMI	-	4K @ 30Hz	x	-	1.00 m
2589594-NW	DisplayPort	HDMI	-	4K @ 30Hz	x	-	2.00 m
2589595-NW	DisplayPort	HDMI	-	4K @ 30Hz	x	-	3.00 m
2589596-NW	DisplayPort	HDMI	-	4K @ 30Hz	x	-	5.00 m
2497577-NW	DisplayPort	HDMI	-	8K @ 60Hz 4K @ 120Hz	x	-	1.00 m
2497578-NW	DisplayPort	HDMI	-	8K @ 60Hz 4K @ 120Hz	x	-	2.00 m
2497579-NW	DisplayPort	HDMI	-	8K @ 60Hz 4K @ 120Hz	x	-	3.00 m
1650574-NW	DisplayPort	DVI	-	Full HD	x	-	0.50 m
1650571-NW	DisplayPort	DVI	-	Full HD	x	-	1.00 m
1404070-NW	DisplayPort	DVI	-	Full HD	x	-	1.80 m
1404071-NW	DisplayPort	DVI	-	Full HD	x	-	5.00 m

N.B.: More details about returning old batteries and rechargeables are available at conrad.com. For more deals and the latest information, please visit our online shop at conrad.com.

MONITOR CABLES

Product ID	Laptop connector	Monitor connector	Bidirectional	Resolution	Copper	FO/ copper hybrid	Length
2269085-NW	Mini DisplayPort	DisplayPort	x	4K @ 60Hz	x	-	0.50 m
2269086-NW	Mini DisplayPort	DisplayPort	x	4K @ 60Hz	x	-	1.00 m
2269087-NW	Mini DisplayPort	DisplayPort	x	4K @ 60Hz	x	-	1.50 m
2269088-NW	Mini DisplayPort	DisplayPort	x	4K @ 60Hz	x	-	2.00 m
2269089-NW	Mini DisplayPort	DisplayPort	x	4K @ 60Hz	x	-	3.00 m
1404072-NW	DVI	HDMI	-	Full HD	x	-	1.80 m
1404073-NW	DVI	HDMI	-	Full HD	x	-	5.00 m
1404065-NW	DVI	DVI	x	4K @ 30 Hz	x	-	1.80 m
2347573-NW	DVI	DVI	x	4K @ 30 Hz	x	-	5.00 m
2347574-NW	DVI	DVI	x	4K @ 30 Hz	x	-	10.00 m
1404165-NW	VGA	VGA	x	HD	x	-	1.00m
1404166-NW	VGA	VGA	x	HD	x	-	1.80m
1404167-NW	VGA	VGA	x	HD	x	-	5.00m
2269083-NW	USB C <sup>®</sup>	DisplayPort	-	4K @ 60Hz	x	-	1.80 m
2300492-NW	USB C <sup>®</sup>	DisplayPort	-	8K @ 60Hz 4K @ 120Hz	x	-	1.00 m
2300491-NW	USB C <sup>®</sup>	DisplayPort	-	8K @ 60Hz 4K @ 120Hz	x	-	2.00 m
2269081-NW	USB C <sup>®</sup>	Mini DisplayPort	-	4K @ 60Hz	x	-	1.80 m
2620873-NW	USB C <sup>®</sup>	USB C <sup>®</sup>	x	8K @ 60Hz	x	-	1.00 m
2617990-NW	Thunderbolt™	Thunderbolt™	x	8K @ 60Hz	x	-	0.80 m
2265795-NW	USB C <sup>®</sup>	HDMI	-	4K @ 60Hz	x	-	0.50 m
2265796-NW	USB C <sup>®</sup>	HDMI	-	4K @ 60Hz	x	-	1.80 m
2265797-NW	USB C <sup>®</sup>	HDMI	-	4K @ 60Hz	x	-	3.00 m



DisplayPort – DisplayPort



DisplayPort – HDMI



DisplayPort – DVI



Mini DisplayPort – DisplayPort



DVI – HDMI



DVI – DVI



VGA – VGA



USB<sup>®</sup> – DisplayPort



USB<sup>®</sup> – Mini DisplayPort



USB<sup>®</sup> – USB<sup>®</sup>



Thunderbolt™ – Thunderbolt™



USB<sup>®</sup> – HDMI

Full product details are available at [conrad.com](http://conrad.com)

## MONITOR ADAPTERS

Over the past years, PC monitor connector designs have either changed or were replaced with different versions. To ensure the compatibility of older monitors with state-of-the-art laptops and docking stations, and vice versa, Renkforce supply a wide variety of adapters. Keep in mind that unidirectionality also applies to adapters.




### MONITOR ADAPTERS

Product ID	Laptop connector	Monitor connector	Monitor connector alternative	Additional outputs	Resolution max.	Short cable	PD
2617019-NW	USB C*	HDMI	-	-	4K @ 60Hz	x	-
2183222-NW	USB C*	HDMI	-	1x USB C* 1x USB A	4K @ 60Hz	x	-
2566838-NW	USB C*	HDMI	-	1x USB C* 1x USB A	4K @ 60Hz	x	yes / 60W
2306538-NW	USB C*	HDMI	VGA	1x USB C* 3x USB A	4K @ 30Hz (HDMI) Full HD (VGA)	x	yes / 60W
2316533-NW	USB C*	HDMI	VGA DVI	-	4K @ 30Hz (HDMI) Full HD (DVI, VGA)	x	-
2339782-NW	USB C*	VGA	-	-	Full HD	x	-
1407508-NW	DisplayPort	HDMI	-	-	4K @ 30Hz	x	-
2373311-NW	DisplayPort	HDMI	-	-	Full HD	-	-
2753481-NW	DisplayPort	HDMI	-	-	4K @ 30Hz	-	-
2798162-NW	DisplayPort	HDMI	-	-	4K @ 30Hz	x	-
2623311-NW	DisplayPort	HDMI	-	-	8K @ 60Hz 4K @ 120Hz	x	-
2252876-NW	DisplayPort	HDMI	VGA	-	4K @ 30Hz (HDMI) Full HD (VGA)	x	-
1404079-NW	DisplayPort	DVI	-	-	Full HD	-	-
1433016-NW	DisplayPort	DVI	-	-	4K @ 30Hz	x	-
1409671-NW	Mini DisplayPort	HDMI	-	-	4K @ 30Hz	x	-
1403558-NW	Mini DisplayPort	HDMI	VGA	-	4K @ 30Hz (HDMI) Full HD (VGA)	x	-
1650567-NW	DVI	VGA	-	-	Full HD	x	-
1404074-NW	DVI	VGA	-	-	Full HD	-	-
1404076-NW	DVI	HDMI	-	-	Full HD	-	-
1404077-NW	HDMI	DVI	-	-	Full HD	-	-
2265789-NW	HDMI	VGA	-	-	Full HD	x	-

N.B.: More details about returning old batteries and rechargables are available at [conrad.com](https://www.conrad.com). For more deals and the latest information, please visit our online shop at [conrad.com](https://www.conrad.com).  
N.B.: HDMI is a registered trademark of HDMI Licensing, LLC.

Stylish and durable aluminium housing

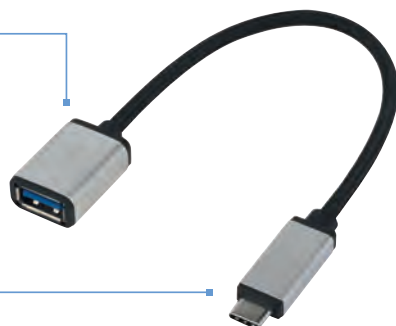

USB C port of laptop or tablet

### USB C® to USB A Port Adapter Cable

- Keep connecting your old peripherals to your PC/laptop
- Enables connecting USB drives to smartphones and tablets
- OTG function – direct data transfer without a PC

Product ID 1629428-NW

Ultra-short length (5 cm incl. plug)



### Lightning Power Bank Charging Adapter

- Hold power bank and iPhone with one hand
- 180° bendability

Product ID 1688019-NW



Back view

### USB A to USB C® Adapter

- Max. speed: 5 Gbps

Product ID 2236153-NW



Back view

### Micro-USB to USB C® Adapter

- Max. speed: 480 Mbps

Product ID 2236419-NW



Back view

### USB C® to Micro-USB Adapter

- Max. speed: 480 Mbps

Product ID 2236154-NW

USB 4® 90-degree adapter, supports PD protocol and 240W quick charging



### USB 4®-compatible USB C® 90-Degree Adapter, 40 Gbps, 5A

- Supports 40 Gbps transfer rates
- Supports 8k@60Hz Audio-Video
- Plug & Play compatibility

Product ID 2622636-NW

Full product details are available at [conrad.com](https://www.conrad.com)

## USB CABLES

These days, at the office workspace, USB ports are omnipresent. Device charging, data transfers, even monitor cables, you name it. Means these cables need to meet a variety of requirements. Renkforce provide a wide range of products, with USB C cables featuring faster data transfer rates and higher charging power, depending on where they are going to be used.



### MFI-CERTIFIED CHARGING CABLES

Product ID	Laptop/PSU connector	iPhone/iPad connector	Max. power	Max. speed	Length	Colour	Features
2497591-NW	USB A	Lightning	30 W @ 15V / 2 A	480 Mbps	1.00 m	Black	Recycled braid sleeve
2497592-NW	USB A	Lightning	30 W @ 15V / 2 A	480 Mbps	2.00 m	Black	Recycled braid sleeve
2497593-NW	USB C*	Lightning	60 W @ 20V / 3 A	480 Mbps	1.00 m	Black	Recycled braid sleeve
2497594-NW	USB C*	Lightning	60 W @ 20V / 3 A	480 Mbps	2.00 m	Black	Recycled braid sleeve
2589597-NW	USB A	Lightning	15 W @ 5V / 3 A	480 Mbps	1.00 m	White	-
2616584-NW	USB A	Lightning	15 W @ 5V / 3 A	480 Mbps	2.00 m	White	-
1362474-NW	USB A	Lightning	12.4 W @ 5V / 2.4 A	480 Mbps	0.95 m	Black	Spiral cable
1667553-NW	USB A	Lightning / USB C* / USB micro	2.5 W @ 5 V / 0.5 A	480 Mbps	0.25 m	Black	Braid sleeve
1533489-NW	USB A	Lightning / USB C* / USB micro	2.5 W @ 5 V / 0.5 A	480 Mbps	0.5 m	Black	Braid sleeve
1667554-NW	USB A	Lightning / USB C* / USB micro	2.5 W @ 5 V / 0.5 A	480 Mbps	1.00 m	Black	Braid sleeve
1667290-NW	USB A	Lightning / USB C* / USB micro	2.5 W @ 5 V / 0.5 A	480 Mbps	1.5 m	Black	Braid sleeve
1667289-NW	USB A	Lightning / USB C* / USB micro	2.5 W @ 5 V / 0.5 A	480 Mbps	3.00 m	Black	Braid sleeve
2497590-NW	USB C*	MagSafe	15 W @ 5V / 3 A	-	2.00 m	White	-



### USB CHARGING CABLES

Product ID	Laptop/PSU connector	Smartphone connector	Max. power	Max. speed	Length	Colour
1429649-NW	USB A	USB C*	36 W @ 12 V / 3.0 A	480 Mbps	1.00 m	Black
1429650-NW	USB A	USB C*	36 W @ 12 V / 3.0 A	480 Mbps	1.50 m	Black
1620632-NW	USB A	USB C*	36 W @ 12 V / 3.0 A	10 Gbps	0.15 m	Black
1620631-NW	USB A	USB C*	36 W @ 12 V / 3.0 A	10 Gbps	0.30 m	Black
1460359-NW	USB A	USB C*	36 W @ 12 V / 3.0 A	10 Gbps	0.50 m	Black
1460360-NW	USB A	USB C*	36 W @ 12 V / 3.0 A	10 Gbps	1.00 m	Black
1460361-NW	USB A	USB C*	36 W @ 12 V / 3.0 A	10 Gbps	1.80 m	Black



N.B.: More details about returning old batteries and rechargeables are available at conrad.com. For more deals and the latest information, please visit our online shop at conrad.com.



## USB CABLES

Product ID	Laptop connector	Device connector	Max. power	Max. speed	Length	Colour	Use
2625959-NW	USB C*	USB C*	240 W @ 48 V / 5 A	480 Mbps	1.00 m	Black	Fast charge
2625961-NW	USB C*	USB C*	240 W @ 48 V / 5 A	480 Mbps	2.00 m	Black	Fast charge
1460356-NW	USB C*	USB C*	100 W @ 20 V / 5 A	20 Gbps	0.50 m	Black	Connection
1460357-NW	USB C*	USB C*	100 W @ 20 V / 5 A	20 Gbps	1.00 m	Black	Connection
1460358-NW	USB C*	USB C*	100 W @ 20 V / 5 A	20 Gbps	1.50 m	Black	Connection
2265788-NW	USB C*	USB C*	100 W @ 20 V / 5 A	20 Gbps	2.00 m	Black	Connection
2269072-NW	USB A	USB B	2.5 W @ 5 V / 0.5 A	480 Mbps	1.80 m	Transparent	Printer cable
2269074-NW	USB A	USB B	2.5 W @ 5 V / 0.5 A	480 Mbps	3.00 m	Transparent	Printer cable
2269073-NW	USB A	USB B	2.5 W @ 5 V / 0.5 A	480 Mbps	5.00 m	Transparent	Printer cable
1487688-NW	USB A	USB B	2.5 W @ 5 V / 0.5 A	480 Mbps	0.30 m	Black	Printer cable
1487689-NW	USB A	USB B	2.5 W @ 5 V / 0.5 A	480 Mbps	0.50 m	Black	Printer cable
1487690-NW	USB A	USB B	2.5 W @ 5 V / 0.5 A	480 Mbps	1.00 m	Black	Printer cable
1420166-NW	USB A	USB B (3.1)	4.5 W @ 5 V / 0.9 A	5 Gbps	0.50 m	Blue	HDD cable
1420168-NW	USB A	USB B (3.1)	4.5 W @ 5 V / 0.9 A	5 Gbps	1.80 m	Blue	HDD cable
1485268-NW	USB A	USB mini	2.5 W @ 5 V / 0.5 A	480 Mbps	0.15 m	Black	Connection
1485269-NW	USB A	USB mini	2.5 W @ 5 V / 0.5 A	480 Mbps	0.30 m	Black	Connection
1365369-NW	USB A	USB mini	2.5 W @ 5 V / 0.5 A	480 Mbps	1.80 m	Black	Connection
1487692-NW	USB A	USB micro	2.5 W @ 5 V / 0.5 A	480 Mbps	0.30 m	Black	Connection
1438740-NW	USB A	USB micro	2.5 W @ 5 V / 0.5 A	480 Mbps	1.00 m	Black	Connection
1574809-NW	USB A	USB micro	2.5 W @ 5 V / 0.5 A	480 Mbps	3.00 m	Black	Connection



## CABLE EXTENSIONS

Product ID	Laptop connector	Device connector	Max. power	Max. speed	Length	Colour	Use
2377610-NW	USB C*	USB C* (port)	60 W @ 20 V / 3 A	20 Gbps	1.00 m	Black	Extension
2377611-NW	USB C*	USB C* (port)	60 W @ 20 V / 3 A	10 Gbps	2.00 m	Black	Extension
1420708-NW	USB A	USB A (port)	4.5 W @ 5 V / 0.9 A	5 Gbps	1.00 m	Blue	Extension
1420710-NW	USB A	USB A (port)	4.5 W @ 5 V / 0.9 A	5 Gbps	3.00 m	Blue	Extension
1487676-NW	USB A	USB A (port)	2.5 W @ 5 V / 0.5 A	480 Mbps	1.00 m	Black	Extension
1487682-NW	USB A	USB A (port)	2.5 W @ 5 V / 0.5 A	480 Mbps	3.00 m	Black	Extension
2523275-NW	USB micro	USB micro (port)	2.5 W @ 5 V / 0.5 A	480 Mbps	1.80 m	Black	Extension

Full product details are available at [conrad.com](https://www.conrad.com)

# DOCKING STATIONS

Docking stations are a very useful accessory to all mobile devices. They are an easy way of expanding the workplace equipment by connecting to a large number of peripherals and screens. Docking stations come with USB C® ports that enable high-speed data transfers and using one single port to control all connected devices.



Product ID	2621177-NW	2621178-NW	2619751-NW
Type description	RF-DKS-903 USB C® 5IN1 DOCK	RF-DKS-901 USB C® 9IN1 DOCK	RF-DKS-800 USB C® 8IN1 DOCK – 8K UHD
Connector A	USB C®	USB C®	USB C®
Connector B	1x HDMI port 1x USB C® port (Power Delivery) 1x USB 3.2 Gen 1 (USB 3.0) 2x USB 2.0	1x HDMI port 1x 3.5 mm jack 1x USB C® port (Power Delivery) 1x USB 3.2 Gen 1 (USB 3.0) 2x USB 2.0 1x RJ45 port (10/100 Mbps) 1x MicroSD card slot 1x SD card slot	1x HDMI port 1x 3.5 mm jack 1x USB C® port (Power Delivery) 1x USB 3.2 Gen 1 (USB 3.0) 2x USB 2.0 1x RJ45 port (10/100 Mbps) 1x MicroSD card slot 1x SD card slot
No. of supported monitors	1	1	2
Max. resolution	3840 x 2160 pixels	3840 x 2160 pixels	1x 7680 x 4320 pixels (30 Hz) / 2x 3840 x 2160 pixels (60 Hz)
Power Delivery	PD 3.0 - USB C® output power: max. 87W (at 100 W input power) (PSU required)	PD 3.0 - USB C® output power: max. 87 W (at 100 W input power) (PSU required)	PD 3.0 - USB C® output power: max. 87 W (at 100 W input power) (PSU required)
Dimensions	28 x 10 x 103 mm	40 x 14 x 1215 mm	45 x 13.8 x 130 mm



Product ID	2249726-NW	2796202-NW
Type description	RF-DKS-650 USB C® 15in1 DOCK	RF-DKS-902 USB C® 15IN1 DOCK + STAND
Connector A	USB C® plug	USB C®
Connector B	3x HDMI port 1x VGA port 2x USB C® port 1x USB C® port (Power Delivery) 4x USB A 3.2 Gen 2 port (USB 3.1) 1x RJ45 port 1x 3.5 mm jack	1x HDMI port (4K) 1x DisplayPort (4K) 1x VGA port (1080p) 3x USB A 3.2 Gen 2 port (USB 3.1) 2x USB 2.0 2x USB C® port 1x USB C® port (Power Delivery) 1x Gigabit RJ45 port (10/100/1000 Mbps) 1x 3.5 mm jack 1x MicroSD card slot 1x SD card slot
No. of supported monitors	4	3
Max. resolution	3840 x 2160 pixels	3840 x 2160 pixels
Power Delivery	PD 3.0 USB C® output power: max. 87 W (at 100 W input power) (PSU required)	PD 3.0 USB C® output power: max. 87 W (at 100 W input power) (PSU required)
Dimensions	63 x 73.5 x 120 mm	300 x 81 x 19 mm

**You may also like:**  
LAPTOP STAND

Product ID	2399949-NW
Suitable for	11" bis 17.3"
Dimensions	240 x 235.5 x 135.5 mm
Features	Stylish open light-weight aluminium design for improved air circulation. Rises screen to eye level. Silicone pad protects and stabilises the laptop.

Full product details are available at [conrad.com](https://conrad.com)



## USB HUBS

USB hubs increase the number of USB ports available in PCs and laptops. They enable connecting multiple USB devices such as printers, flash memory, smartphones, webcams and external HDDs, at the same time. USB hubs use Plug & Play standards which means they set themselves up automatically. They come in a compact design which makes them the perfect laptop accessories.



1234385

### USB HUBS & SWITCHES

Product ID	Connector	No. of USB outputs	SD card slot	microSD card slot	USB chargingport	PSU included	Data throughput	Features	Colour	Dimensions
1234385-NW	USB A	4	-	-	-	-	5 Gbps	Aluminium housing	Aluminium	113 x 16 x 35 mm
1687472-NW	USB C*	4	-	-	-	-	5 Gbps	Aluminium housing	Silver	114 x 18.4 x 37 mm
1614145-NW	USB A	4	-	-	-	-	5 Gbps	Compact design	Black	88 x 16 x 56 mm
1295719-NW	USB A	4	-	-	-	-	5 Gbps	Output on top	Black	78 x 35 x 62 mm
1268677-NW	USB A	4	-	-	1	x	5 Gbps	Charging port	Black	105 x 25 x 60 mm
1342481-NW	USB A	3	1	1	-	-	5 Gbps	Memory card reader	Black	100 x 42 x 16 mm
1687474-NW	USB C*	3	1	1	-	-	5 Gbps	Memory card reader	Silver	143 x 17.7 x 36.5 mm
1607017-NW	USB A	7	-	-	1	x	5 Gbps	Individual output switches/Quick charge port	Black	37 x 25 x 166 mm
1615863-NW	USB A	7	-	-	-	-	480 Mbps	Individual output switches	Black	165 x 24.2 x 35.5 mm
1687470-NW	USB A	4	-	-	-	-	480 Mbps	Individual output switches	Black	105 x 24.2 x 35.5 mm
1628714-NW	USB A	4	-	-	-	-	480 Mbps	One main switch for all outputs	Black	18 x 22 x 70 mm
1318454-NW	USB A	4	-	-	-	x	5 Gbps	Individual output switches, Wall/desk mount	Black	126 x 31 x 55 mm
1597226-NW	USB A	7	-	-	-	x	480 Mbps	Wall/desk mount	Black	186 x 20 x 45 mm


Full product details are available at [conrad.com](https://www.conrad.com)

## NETWORK CABLES


Fast and reliable LAN connections boost productivity when working from home and at the office. CAT 5 and CAT 6 network cables enable high-speed data transfer and ensure adequate signal quality. Renkforce provide a comprehensive range of solutions that cover a variety of scenarios, distances and other requirements.



### NETWORK CABLES

Product ID	Length	Shielding	Specification	Shared product features
2362135-NW	0.50 m	S/FTP	CAT 6	 <p><b>AWG: 27</b>  <b>Colour: grey</b>  <b>Core made of: copper</b>  <b>Features: gold-plated contacts, latch protection, flame-resistant</b></p>
2362146-NW	0.15 m	S/FTP	CAT 6	
2362145-NW	0.25 m	S/FTP	CAT 6	
2362144-NW	1.00 m	S/FTP	CAT 6	
2362467-NW	2.00 m	S/FTP	CAT 6	
2362132-NW	3.00 m	S/FTP	CAT 6	
2362133-NW	5.00 m	S/FTP	CAT 6	
2362134-NW	10.00 m	S/FTP	CAT 6	
2362130-NW	15.00 m	S/FTP	CAT 6	
2362131-NW	20.00 m	S/FTP	CAT 6	
2362143-NW	30.00 m	S/FTP	CAT 6	
1383278-NW	0.25 m	U/FTP	CAT 6a	
1383279-NW	0.50 m	U/FTP	CAT 6a	
1383280-NW	1.00 m	U/FTP	CAT 6a	
1383281-NW	3.00 m	U/FTP	CAT 6a	
1383282-NW	5.00 m	U/FTP	CAT 6a	
1383283-NW	10.00 m	U/FTP	CAT 6a	
1383284-NW	15.00 m	U/FTP	CAT 6a	
1383285-NW	20.00 m	U/FTP	CAT 6a	

### NETWORK CABLE EXTENSIONS

Product ID	Length	Shielding	Specification	Shared product features
1464708-NW	0.50 m	F/UTP	CAT 5e	 <p><b>AWG: 26</b>  <b>Colour: Black</b>  <b>Core made of: copper</b>  <b>Features: gold plated contacts, latch protection</b></p>
1464707-NW	1.00 m	F/UTP	CAT 5e	
1464710-NW	3.00 m	F/UTP	CAT 5e	
1464709-NW	5.00 m	F/UTP	CAT 5e	

N.B.: More details about returning old batteries and rechargeables are available at conrad.com. For more deals and the latest information, please visit our online shop at conrad.com.



NETWORK CABLES

Product ID	Colour	Length	Shielding	Specification	Shared product features
2623313-NW	Yellow	0.15 m	S/FTP	CAT 6a	<p style="text-align: center;">AWG: 27 Core made of: copper Features: latch protection, flame resistant</p>
2617816-NW	Yellow	0.25 m	S/FTP	CAT 6a	
2612322-NW	Yellow	0.50 m	S/FTP	CAT 6a	
2612325-NW	Yellow	1.00 m	S/FTP	CAT 6a	
2544324-NW	Yellow	2.00 m	S/FTP	CAT 6a	
2576834-NW	Yellow	3.00 m	S/FTP	CAT 6a	
2544326-NW	Yellow	5.00 m	S/FTP	CAT 6a	
2576832-NW	Yellow	10.00 m	S/FTP	CAT 6a	
2544323-NW	Green	0.15 m	S/FTP	CAT 6a	
2582292-NW	Green	0.25 m	S/FTP	CAT 6a	
2528208-NW	Green	0.50 m	S/FTP	CAT 6a	
2528210-NW	Green	1.00 m	S/FTP	CAT 6a	
2544325-NW	Green	2.00 m	S/FTP	CAT 6a	
2612329-NW	Green	3.00 m	S/FTP	CAT 6a	
2568486-NW	Green	5.00 m	S/FTP	CAT 6a	
2612323-NW	Green	10.00 m	S/FTP	CAT 6a	
2731199-NW	Green	15.00 m	S/FTP	CAT 6a	
2521988-NW	Red	0.15 m	S/FTP	CAT 6a	
2521987-NW	Red	0.25 m	S/FTP	CAT 6a	
2522025-NW	Red	0.50 m	S/FTP	CAT 6a	
2521986-NW	Red	1.00 m	S/FTP	CAT 6a	
2521977-NW	Red	2.00 m	S/FTP	CAT 6a	
2523749-NW	Red	3.00 m	S/FTP	CAT 6a	
2521985-NW	Red	5.00 m	S/FTP	CAT 6a	
2521976-NW	Red	10.00 m	S/FTP	CAT 6a	
2521975-NW	Red	15.00 m	S/FTP	CAT 6a	
2523728-NW	Blue	0.25 m	S/FTP	CAT 6a	
2522488-NW	Blue	0.50 m	S/FTP	CAT 6a	
2522019-NW	Blue	1.00 m	S/FTP	CAT 6a	
2523750-NW	Blue	2.00 m	S/FTP	CAT 6a	
2523729-NW	Blue	3.00 m	S/FTP	CAT 6a	
2523730-NW	Blue	5.00 m	S/FTP	CAT 6a	
2521959-NW	Blue	10.00 m	S/FTP	CAT 6a	
2521960-NW	Blue	15.00 m	S/FTP	CAT 6a	
2528209-NW	Blue	20.00 m	S/FTP	CAT 6a	
2616755-NW	Blue	30.00 m	S/FTP	CAT 6a	
2522024-NW	Grey	0.15 m	S/FTP	CAT 6a	
2523755-NW	Grey	0.25 m	S/FTP	CAT 6a	
2523747-NW	Grey	0.50 m	S/FTP	CAT 6a	
2523746-NW	Grey	1.00 m	S/FTP	CAT 6a	
2523745-NW	Grey	2.00 m	S/FTP	CAT 6a	
2523744-NW	Grey	3.00 m	S/FTP	CAT 6a	
2523743-NW	Grey	5.00 m	S/FTP	CAT 6a	
2521974-NW	Grey	10.00 m	S/FTP	CAT 6a	
2521973-NW	Grey	15.00 m	S/FTP	CAT 6a	
2612328-NW	Grey	20.00 m	S/FTP	CAT 6a	
2595504-NW	Grey	30.00 m	S/FTP	CAT 6a	

Full product details are available at [conrad.com](http://conrad.com)

# USB HUBS

Compact and durable USB hubs that can be fitted to walls, or put inside cupboards and under desks to keep things neat. Moreover, connecting and disconnecting cables requires one hand only as you don't need to hold the hub using the other. Renkforce also supply products that come with an individual switch for each port.



## USB HUBS

Product ID	1299048-NW	1318453-NW	1089874-NW
No. of USB outputs	13	7	7
Dimensions	122 x 20 x 45 mm	187 x 20 x 45 mm	187 x 31 x 55 mm
Transfer rate	5 Gbps	5 Gbps	5 Gbps
Power supply unit	12 V / 5 A mains	5 V / 4 A mains	5 V / 4 A mains
Features	Aluminium housing Wall mount Quick charge port	Steel housing Wall mount	Steel housing Individual switches Wall mount