

HIRSCHMANN MOBILITY



CELLULAR (2G/3G) Adhesive Antenna

MCA 1890 SLIM
Pt no.
602-311-002

- Easy interior windscreen mounting
- Doesn't interfere the car design


Subject to alterations

Technical data



Dimensions	22 x 115 mm	
Weight	63 g	
Temperature range	-40°C - + 85°C	
Protection class	IP50 (acc. IEC 60529, EN 60529)	
GPS		
Frequency range	GSM 850:	824 - 894 MHz
	GSM 900:	880 - 960 MHz
	GSM 1800:	1710 - 1880 MHz
	GSM 1900:	1850 - 1990 MHz
	UMTS:	1900 - 2170 MHz
Impedance	50 Ohm	
Gain	0 dB	
Load capacity	max.	8 W pulsed acc. GSM standard
Cable type	RG 174	
Cable length	2500 mm	
Connector	FME female	
Packaging	Carton	

Subject to alterations

Technical drawings




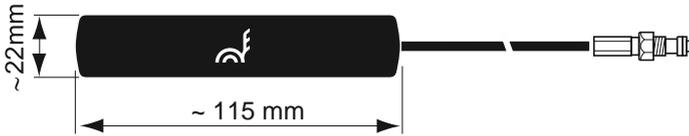


Installation

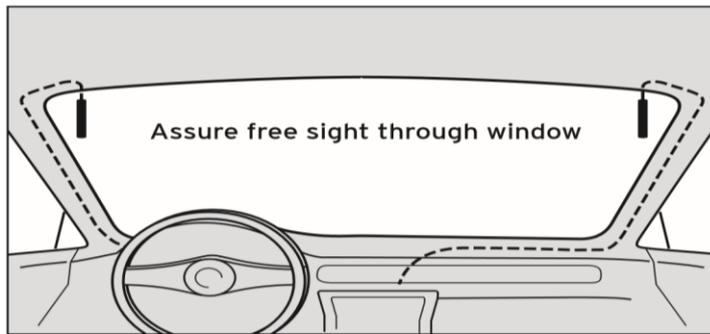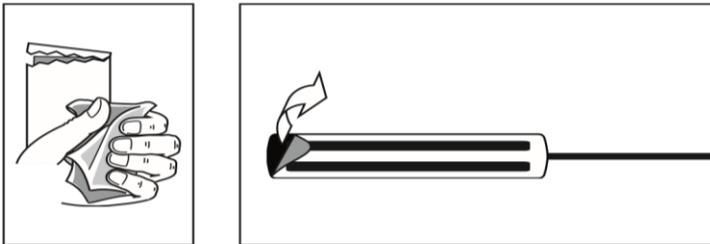

Antenna diagrams

Typ. VSWR

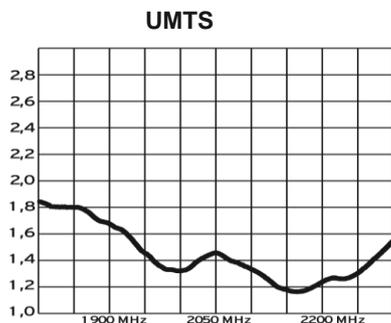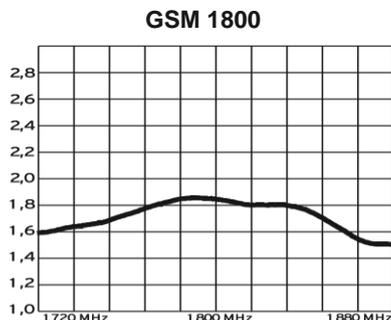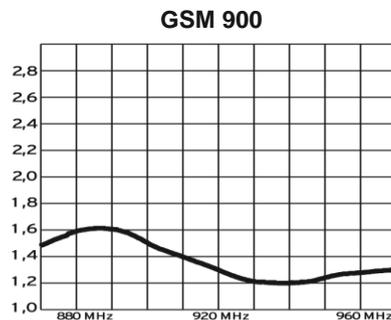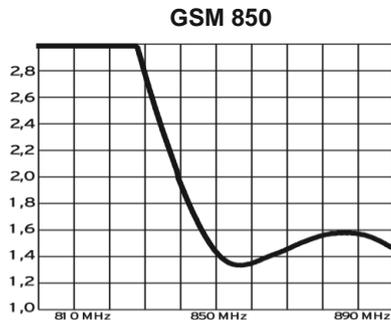

www.te.com/hirschmann-mobility
hirschmann-mobility@te.com

TE, TE Connectivity, TE connectivity (logo), and EVERY CONNECTION COUNTS are trademarks.
Hirschmann is a trademark.

GSM and UMTS are trademarks.

The information given herein, including drawings, illustrations and schematics which are intended for illustration purposes only, is believed to be reliable. However, TE Connectivity makes no warranties as to its accuracy or completeness and disclaims any liability in connection with its use. TE Connectivity's obligations shall only be as set forth in TE Connectivity's Standard Terms and Conditions of Sale for this product and in no case will TE Connectivity be liable for any incidental, indirect or consequential damages arising out of the sale, resale, use or misuse of the product. Users of TE Connectivity products should make their own evaluation to determine the suitability of each such product for the specific application.

© 2019 TE Connectivity Ltd. family of companies All Rights Reserved.