


C-RC 25/M8 DIN

Obj.č.: 3240101


<http://eshop.phoenixcontact.cz/phoenix/treeViewClick.do?UID=3240101>

 Kulaté kabelové oko, neizolované, 25 mm², M8

Údaje

| | |
|----------------------|--|
| EAN |  4 046356 453189 |
| Balení | 100 ks |
| Celní tarif | 85369010 |
| Váha brutto v kusech | 0,00782 kg |
| Informace v katalogu | Strana 454 (CAT-5-2013) |

Poznámky k produktu

 WEEE/RoHS-compliant since:
23.09.2008


<http://www.download.phoenixcontact.com>
 Please note that the data given here has been taken from the online catalog. For comprehensive information and data, please refer to the user documentation. The General Terms and Conditions of Use apply to Internet downloads.

Technické údaje

Obecné

| | |
|----------------------------|----------|
| Délka (b) | 33 mm |
| Šířka (a) | 16 mm |
| Barva | stříbrná |
| Délka odstranění izolace | 14 mm |
| Teplota prostředí (provoz) | 110 °C |
| Materiálem | měď |

| | |
|--|--------|
| Délka pouzdra izolačního materiálu (c) | 11 mm |
| Vnitřní rozměr izolačního límce (d) | 7,5 mm |
| Vzdálenost středu pouzdra izolačního materiálu (e) | 14 mm |
| Vnitřní průměr (f) | 8,4 mm |
| Tloušťka materiálu (g) | 1,5 mm |

Certifikáty/Osvědčení


Aprobace

Vyžádané aprobace:

Aprobace z:

Výkres/schéma

Výkres v měřítku

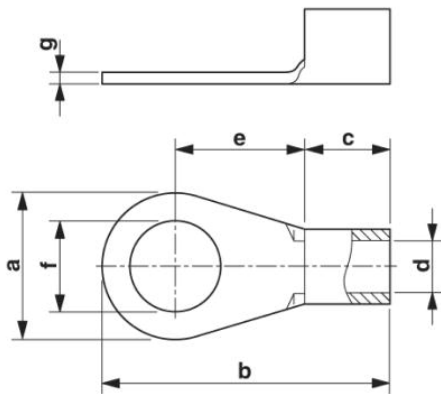

Adresa

PHOENIX CONTACT, s.r.o.
Dornych 47
617 00 Brno, Czech Republic
Telefon +420 542 213 401
Fax +420 542 213 701
<http://www.phoenixcontact.cz>



© 2013 Phoenix Contact
Technické změny vyhrazeny.