



Formgods retvinklet VG type


Helashrink 1100 serien højrevinklet med læbe

Egenskaber og fordele


- Anvendes sammen med cirkulær rillet adaptor
- Giver aflastning samt forsegling



Helashrink 1152-4-G efter krympning.

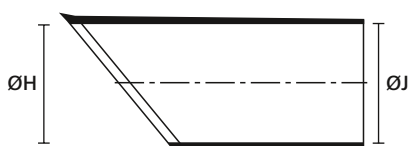

a. Formgods før krymp (som leveret)

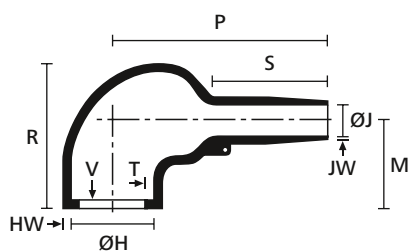

b. Formgods efter krympning



Helashrink 1152-4-G som leveret.

TYPE	Ø H min. a	Ø H max. b	Ø J min. a	Ø J max. b	P ± 10%	R ± 10%	HW ± 20%	JW ± 20%	V max.	T ± 20%	M nom.	S nom.	Efter VG norm	EAN	Bestillingsnr.
1152-4-G	24,0	10,5	24,0	6,0	26,0	25,0	1,3	0,5	3,3	1,0	19	10,0	VG 95343 T06 E 001 A	5022660635090	411-52480
1154-4-G	30,0	15,5	30,0	6,0	32,0	27,0	1,5	0,8	3,3	1,0	19	12,0	VG 95343 T06 E 002 A	5022660635106	411-54480
1155-4-G	31,0	18,0	31,0	7,0	40,0	31,0	1,8	1,0	3,3	1,0	21	15,0	VG 95343 T06 E 003 A	5022660635113	411-55480
1156-4-G	36,0	22,5	36,0	8,5	46,0	38,0	1,8	1,0	3,3	1,0	26	15,0	VG 95343 T06 E 004 A	5022660635120	411-56480
1157-4-G	43,0	28,5	43,0	10,0	55,0	45,0	2,0	1,0	3,3	1,7	30	16,0	VG 95343 T06 E 005 A	5022660635137	411-57480
1158-4-G	60,0	35,0	60,0	16,0	80,0	54,0	3,3	1,5	3,3	1,7	35	30,0	VG 95343 T06 E 006 A	5022660635144	411-58480
1159-4-G	66,0	45,0	66,0	17,0	108,0	68,0	3,8	2,0	3,3	2,0	42	51,0	VG 95343 T06 E 007 A	5022660635151	411-59480
1160-4-G	82,0	61,0	82,0	25,0	118,0	84,0	4,0	4,0	3,3	2,0	52	39,0	VG 95343 T06 E 008 A	5022660635168	411-60480

Alle dimensioner i mm. Der tages forbehold for tekniske ændringer.