


DBY-23415 B415

Uhindret rækkevidde	100 m
Antal melodier	16
Strømforsyning	
Lydstyrkejustering	
Nem isættelse	Ja
Decibelklassificering	80 dB
Strømforsyning dørklokke	
Strømtiktype	C - CEE 7/16 (flat plug)
Radiofrekvens	433 MHz

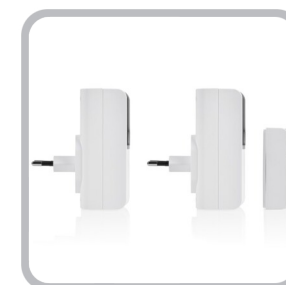

: x x (cm): 15 x 17 x 8.8 | : 8711658446707
(kg): 0.323 | (kg): 0.244

: x x (cm): 39.5 x 39.5 x 56.5 | : 8711658446639
(kg): 9.924

:: 24 | : 144 | x : 3 x 2 | / / : 7623 / 15791 / 17696

