


DIN 431

Rohrmuttern

Form B

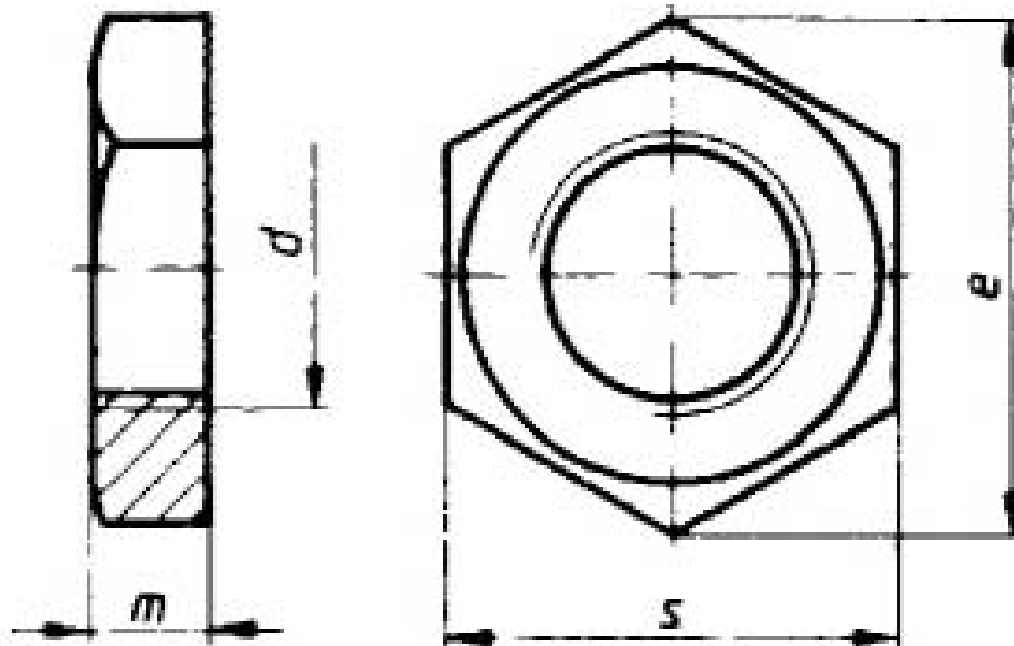

d	s	e	m min
G 1/8	19	20,88	6
G 1/4	22	23,91	6
G 3/8	27	29,56	7
G 1/2	32	35,03	8
G 5/8	32	35,03	8
G 3/4	36	39,55	9
G 7/8	41	45,20	9
G 1	46	50,85	10
G 1 1/4	55	60,79	11
G 1 1/2	60	66,44	12
G 2	75	82,60	13