


Bedienungsanleitung

Mantelthermoelement
K625C0150-10

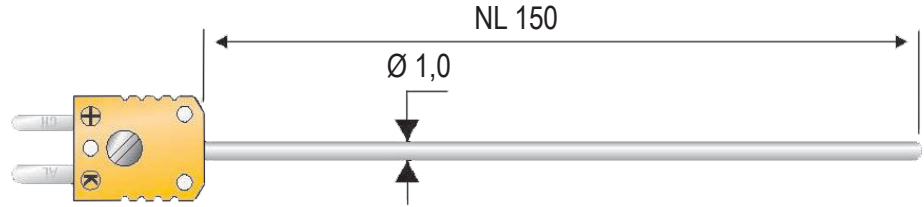

1. Thermoelement NiCr-Ni, Typ K, mit Miniaturstecker (gelb oder grün) am Messgerät in die dafür vorgesehene Buchse einstecken.
2. Messwert am eingeschalteten Messgerät ablesen.
3. Messbereich des Mantelthermoelements -200°C bis +1100°C

B+B Thermo-Technik GmbH

Heinrich-Hertz-Straße 4, D-78166 Donaueschingen

Tel. +49 771 83160, Fax +49 771 831650

info@bubthermo.de, www.bubthermo.de

www.bubthermo.de




Operating Instruction

Mineral Insulated Thermocouple
K625C0150-10

B+B Thermo-Technik GmbH

Heinrich-Hertz-Straße 4, D-78166 Donaueschingen
Phone +49 771 83160, Fax +49 771 831650
info@bubthermo.de, www.bubthermo.com

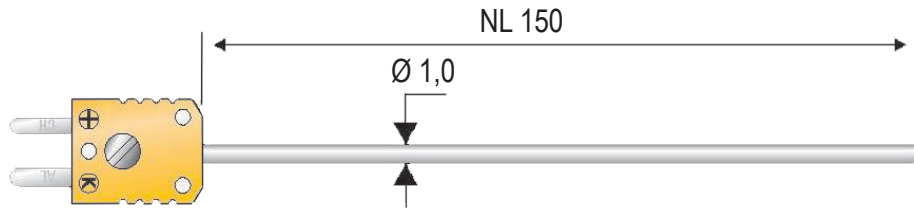

1. Plug in the Mineral Insulated Thermocouple NiCr-Ni, Type K with Miniature Plug (yellow or green) into the destined socket at the measurement device.
2. Read out the measured value of the measurement device.
3. Measuring range of Mineral Insulated Thermocouple $-200^{\circ}\text{C}\dots+1100^{\circ}\text{C}$ ($-328^{\circ}\text{F}\dots+2012^{\circ}\text{F}$)

www.bubthermo.com