


DIN 935-1

Sechskant-Kronenmuttern

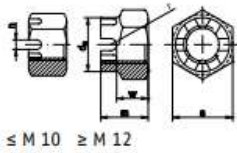

Maße	M 4	M 5	M 6	M 8	M 10	M 12	M 14	M 16
d _{e max.}	-	-	-	-	-	16	18	22
m	5	6	7,5	9,5	12	15	16	19
n _{min.}	1,2	1,4	2	2,5	2,8	3,5	3,5	4,5
S _{ISO/DIN}	7	8	10	13	16/17	18/19	21/22	24
W _{max.}	3,2	4	5	6,5	8	10	11	13
Splint	1x10	1,2x12	1,6x14	2x16	2,5x20	3,2x22	3,2x25	4x28
Maße	M 18	M 20	M 22	M 24	M 27	M 28*	M 30	M 32*
d _{e max.}	25	28	32	34	38	38	42	46
m	21	22	26	27	30	30	33	35
n _{min.}	4,5	4,5	5,5	5,5	5,5	5,5	7	7
S _{ISO/DIN}	27	30	34/32	36	41	41	46	50
W _{max.}	15	16	18	19	22	22	24	26
Splint	4x32	4x36	5x36	5x40	5x45	5x50	6,3x50	6,3x56
Maße	M 33	M 36	M 38*	M 39	M 40*	M 42	M 45	M 48
d _{e max.}	46	50	55	55	55	58	62	65
m	35	38	40	40	48	46	48	50
n _{min.}	7	7	7	7	7	9	9	9
S _{ISO/DIN}	50	55	60	60	60	65	70	75
W _{max.}	26	29	31	31	31	34	36	38
Splint	6,3x56	6,3x63	6,3x70	6,3x71	6,3x70	8x71	8x80	8x80
Maße	M 52	M 56	M 60	M 64	M 68	M 72	M 76	M 80
d _{e max.}	70	75	80	85	90	95	100	105
m	54	57	63	66	69	73	76	79
n _{min.}	9	9	11	11	11	11	11	11
S _{ISO/DIN}	80	85	90	95	100	105	110	115
W _{max.}	42	45	48	51	54	58	61	64
Splint	8x90	8x100	10x100	10x100	10x112	10x112	10x125	10x140