


DIN 7965

Einschraubmuttern "RAMPA-Muffen"
(Schraubdübel)

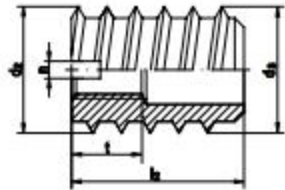

Maße	M 3	M 4	M 5	M 6	M 8	M 10	M 12
d_2	6	8	10	12	16	18,5	22
d_3	4,5	5,5	7,5	9,5	12,5	15	18
l_2	5	6	7	9	11	13	16
n	1	1,2	1,6	2	2,5	3	3
t	2	2	3	3	4	5	5
für Bohrung $\varnothing$	5,0	6,5	8,5	10,5	14,5	17	20