


Achshalter

DIN 15058

Achshalter (für Hebezeuge)

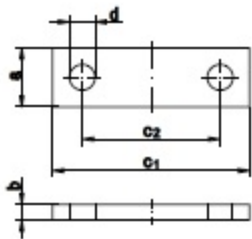

a x b = Nennmaß

Maße	20 x 5	25 x 6	30 x 8	40 x 10	50 x 12
c_1	60	80	100	140	190
c_2	36	50	70	100	140
d	9	11	13	17	21
für Achs \varnothing	16 - 25	25 - 40	40 - 63	63 - 100	100 - 160