


Artikel-Nr.: 251283


Bez.: UHF-Aufdrehstecker, Löt Ausführung für Aircell 7

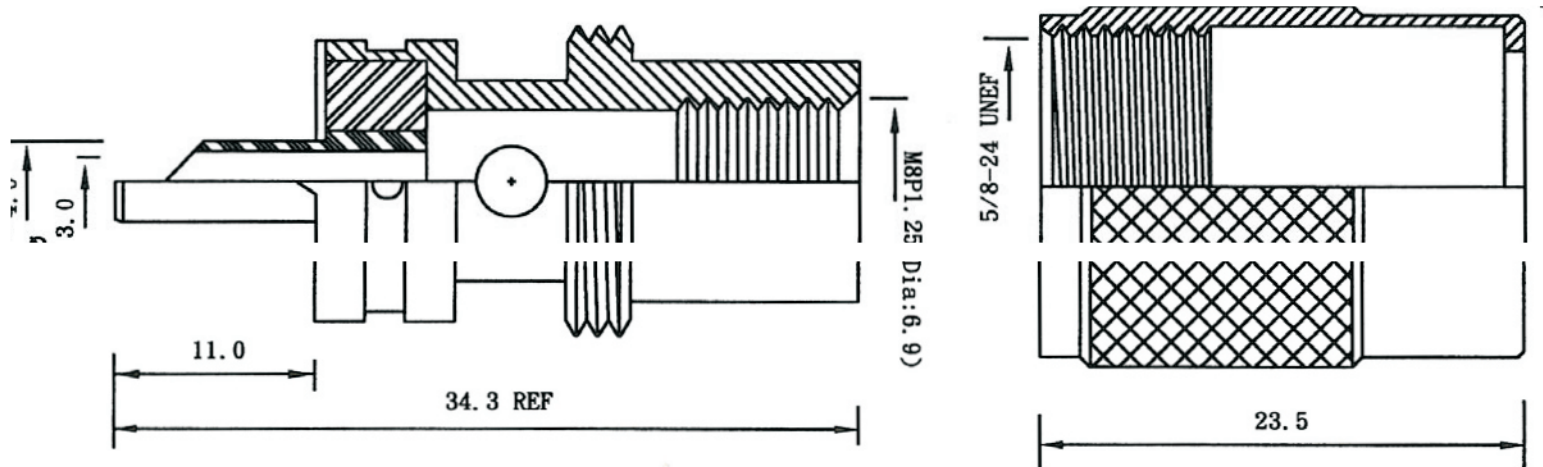

Impedance	Impedance
Frequency range	0-300 MHz
Voltage rating	500 volts peak
Temperature range	Teflon insulations: -65° C to 165° C
Mating	5/8-24 UNEF threaded coupling

No	Description	Material	Finish
4	Shell	Brass	Nickel
3	Insulator	Teflon	White
2	Contact	Brass	Gold
1	Body	Brass	Nickel

recommended
Cable Stripping

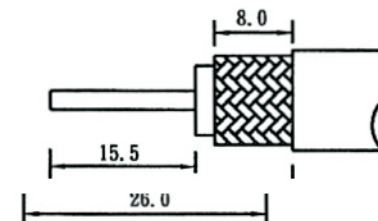

NOTE: FINISH (PLATING THICKNESS IN MICRO-INCH)

1. BODY/CONTACT: BRASS PER JIS-C3604
2. INSULATION: TEFLON PER ASTM D1457 AND ASTM D17
3. CONNECTOR INTERFACE PER MIL-STD-348A
4. PART TO BE CLEAN AND FREE BURRS
5. NICKEL PL 70 u" THICK OVER COPPER STRIKE
6. GOLD PL 1-3u" OVER NICKEL PL 70 u" THICK OVER COPPER STRIKE

www.bkl-electronic.de

Technische Änderungen vorbehalten. Ausführungen können variieren. Sollten Sie ein Muster benötigen kontaktieren Sie uns bitte.

BKL-ELECTRONIC Kreimendahl GmbH • Märkenstück 14 • 58509 Lüdenscheid

Tel: +49 (0)2351-3621-0 • Fax: +49 (0)2351-3621-29 • info@bkl-electronic.de

