

CODE-CODICE: 00498
ITEM-ARTICOLO: BS/5

wall mounting speaker bracket, adjustable, RAL9005
supporto cassa a muro, orientabile, RAL9005



2,30kg



12 pieces - pezzi:
0,107m3; 30,50kg



40kg



o 36mm



o 35mm



120°




45°



1,5/2/2,5mm



9005

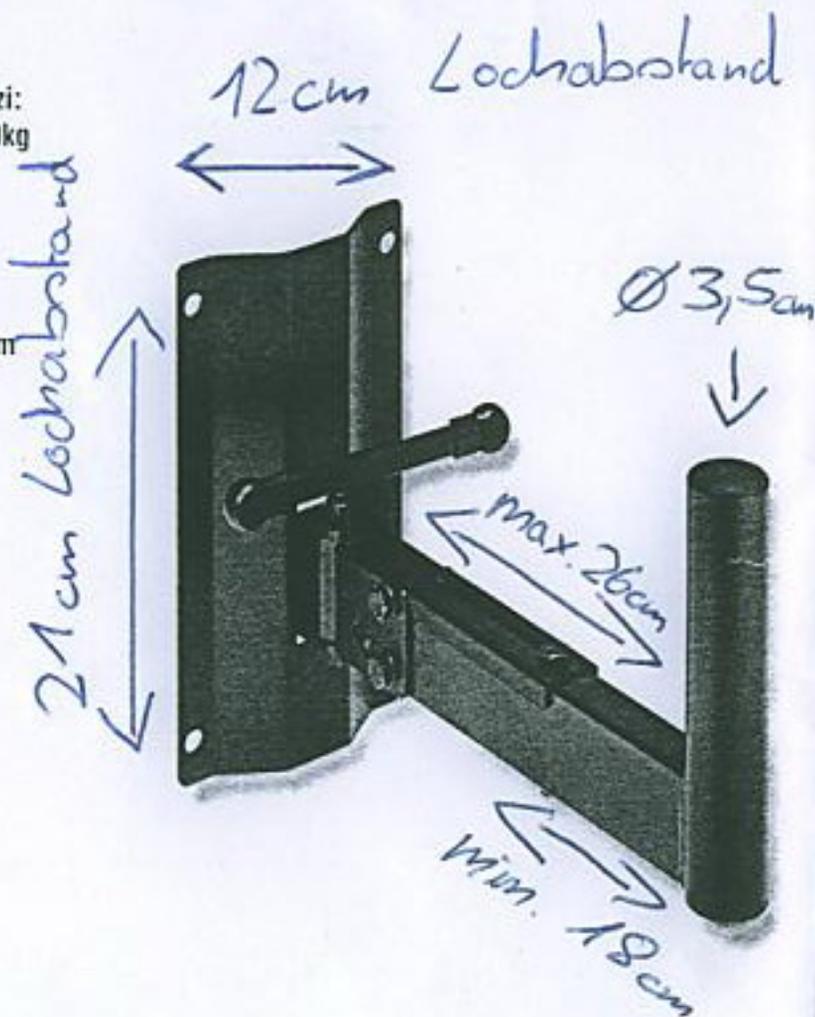

Adjustable wall mounting bracket with arm L=260mm and male attachment H=120mm, \varnothing 35mm to hold speaker. The arm with an adjustable support to clamp the speaker swivels in the horizontal plane and may be tilted. Position of support from centre of male attachment: min. 180mm, max. 260mm. Wall plate 250x140mm with 4 holes \varnothing 10mm to fix bracket.

Supporto orientabile da muro con braccio L=260mm con attacco maschio H=120mm, da \varnothing 35mm per l'applicazione della cassa. Il braccio orientabile orizzontalmente e verticalmente è provvisto di una guida per l'arresto della cassa. Posizione della guida dal centro dell'attacco maschio: min. 180mm, max. 260mm. L'ancoraggio del supporto al muro può essere effettuato tramite 4 fori \varnothing 10mm, posizionati su una piastra di 250x140mm