

2- und 3-polig, IP 66

Fronteinbau Zentralbefestigung 22 mm



2-/3-polig



 
Dauerstrom (I _N /I _{th})	Schaltleistung AC-23B (A)	Frontschild	Artikelnummer	ab Lager lieferbar
2-polig				
	230 V			
20 A	1,5 kW	64 x 64	KG10B T202/01 FT2	●
3-polig				
	3 x 400 V			
20 A	5,5 kW	64 x 64	KG10B T203/01 FT2	●
25 A	7,5 kW	64 x 64	KG20B T203/01 FT2	●
32 A	11 kW	64 x 64	KG32B T203/01 FT2	●

Dauerstrom (I _N /I _{th})	Schaltleistung AC-23B (A)	Frontschild	Artikelnummer	ab Lager lieferbar
2-polig				
	230 V			
20 A	1,5 kW	64 x 64	KG10B T102/01 FT2	
3-polig				
	3 x 400 V			
20 A	5,5 kW	64 x 64	KG10B T103/01 FT2	●
25 A	7,5 kW	64 x 64	KG20B T103/01 FT2	●
32 A	11 kW	64 x 64	KG32B T103/01 FT2	●



2-polig



3-polig



Frontschild	Bügel-Ø	Anzahl Schösser
64 x 64	9	3

 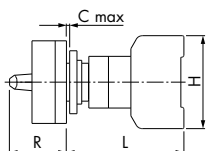

	A	L	G	H	R	C max
KG10B 2-polig	64	57,4	48	50	40,1	6
KG10B 3-polig	64	66,9	48	50	40,1	6
KG20B	64	68,3	42	54	40,1	6
KG32B	64	68,3	42	54	40,1	6

