



Anwendungen	Consumer
	Data Data Processing
	Industrial
Typ	S20K275
Status	Production
Produktmarke	EPCOS




Grösse	
Rastermaß (e)	10.00mm ±1.00mm
Körperbreite (w)	21.50mm Max.
Körperdicke (th)	5.40mm Max.
Körperhöhe(h)	25.50mm Max.
Leitungslänge (l)	25.00mm Min.
Drahtdurchmesser (d)	1.00mm ±0.05mm
Detaillierte Grösseninformationen	Please refer to the catalog

Elektrische Kennwerte	
Maximale Betriebsspannung [DC]	350V
Maximale Betriebsspannung [AC]	275Vrms
Nennentladestrom In [8/20µs, 15times]	3kA
Maximum Stoßstrom Imax [8/20µs, 1time]	8kA
Energieabsorption	151J
Kapazität (Typ.)	850pF

Weiteres	
Betriebstemperaturbereich	Please refer to the catalog
Lötverfahren	Please refer to the document (Soldering Instructions)
Sicherheitsstandard	Please refer to the document (Approvals)
AEC-Q200	NO
Verpackungsinformation	Please refer to the document (Taping, Packaging and Lead Configuration)



Darstellung der Eigenschaften(Dies sind Referenzwerte. Sie stellen nicht die tatsächlichen Produkteigenschaften dar.)

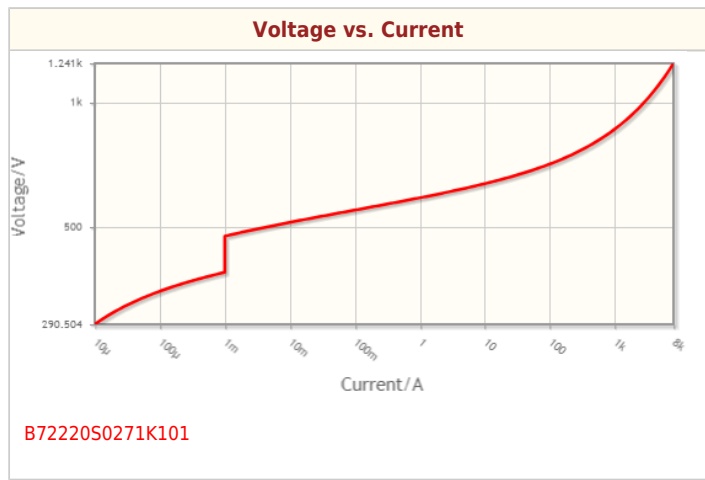

! Images are for reference only and show exemplary products.
! This PDF document was created based on the data listed on the TDK Corporation website.
! All specifications are subject to change without notice.



Dazugehörige Bilder

