



Einrastpuffer mit Zapfen


Material: siehe Tabelle (VTD-91, VTD-93, VTD-95)
Farbe: schwarz

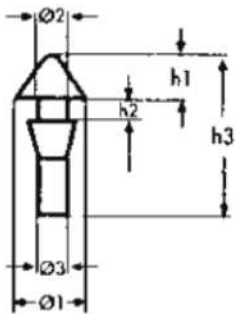

Artikel-Nr.	Material Shore A °	Maße			h1	h2	h3	MOQ Stück
		ø 1	ø 2	ø 3				
 1304-01	EPDM 62	8,5	5,0	3,0	2,0	3,0	10,9	500
 1273-01	EPDM 50	8,7	3,6	2,6	5,0	1,4	15,1	500
 1300-01	EPDM 62	10,0	5,5	3,1	4,0	1,0	14,5	500
 1301-01	EPDM 62	10,0	5,5	3,1	4,0	2,0	15,4	500
 1274-01	EPDM 50	10,0	4,0	3,0	6,8	1,4	18,3	500
 1264-01	EPDM 50	10,3	3,7	2,6	5,0	1,5	14,9	500
 1261-01	EPDM 50	10,3	3,7	2,5	7,2	0,7	16,2	500
 1259-01	CR 50	10,3	3,7	2,5	8,4	0,6	17,3	500
 1320-01	EPDM 62	12,0	4,0	3,0	4,5	2,5	18,4	500
 1336-01	EPDM 50	13,0	6,0	4,8	4,7	1,5	13,8	500
 1339-01	EPDM 62	13,0	6,0	4,8	6,5	1,5	15,8	500
 1340-01	EPDM 50	13,0	6,0	4,8	7,0	2,5	19,0	500
 1337-01	EPDM 62	13,0	4,6	4,5	7,5	1,2	20,0	500
 1343-01	EPDM 62	13,0	5,5	4,4	12,0	3,0	26,2	500
 1344-01	EPDM 62	14,2	6,0	4,0	6,5	1,9	23,4	500
 1338-01	EPDM 62	14,2	6,0	4,0	8,7	1,5	25,6	500
 1341-01	EPDM 50	17,5	8,0	3,9	13,3	0,8	25,2	500

Softpuffer

Material: siehe Tabelle (VTD-93)
Farbe: schwarz

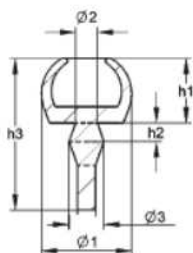

Artikel-Nr.	Material Shore A °	Maße			h1	h2	h3	MOQ Stück
		ø 1	ø 2	ø 3				
 1279-01	EPDM 38	10,0	2,5	4,0	6,0	2,5	19,5	500
 1280-01	EPDM 38	14,5	3,5	5,5	10,0	2,5	23,6	500