
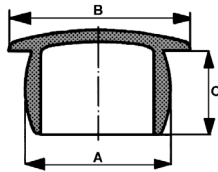


## Dichtungsstopfen / Lochstopfen



Material: LD-PE (SK-03)

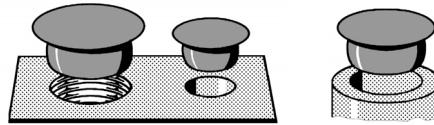

Artikel-Nr.	Farbe	Maße			MOQ Stück
		A	B	C	
055 0021 000 03	natur	2,1	3,5	7,0	1000
055 0025 000 03	natur	2,6	12,0	4,0	1000
055 0026 000 03	natur	2,7	12,0	6,0	1000
055 0032 000 03	natur	3,3	12,0	6,0	1000
054 0449 113 03	weiß	4,4	9,0	5,2	1000
054 0449 220 03	schwarz	4,4	9,0	5,2	1000
055 0044 000 03	natur	4,4	9,0	5,2	1000
054 0477 600 03	weiß	4,6	7,0	5,0	1000
054 0477 699 03	schwarz	4,6	7,0	5,0	1000
055 0047 000 03	natur	4,7	7,0	5,0	1000
055 0052 000 03	natur	5,1	11,0	6,0	100
054 0542 113 03	weiß	5,4	12,0	7,5	1000
054 0542 220 03	schwarz	5,4	12,0	7,5	1000
055 0054 000 03	natur	5,4	12,0	7,5	1000
054 0545 600 03	weiß	5,4	15,0	7,5	1000
054 0545 699 03	schwarz	5,4	15,0	7,5	1000
054 0601 113 03	weiß	6,0	11,0	7,0	1000
054 0601 220 03	schwarz	6,0	11,0	7,0	1000
055 0060 000 03	natur	6,0	11,0	7,0	1000
054 0602 600 03	weiß	6,0	12,0	7,0	1000
054 0602 699 03	schwarz	6,0	12,0	7,0	1000
054 0605 600 03	weiß	6,0	15,0	7,0	1000
054 0605 699 03	schwarz	6,0	15,0	7,0	1000
055 0066 000 03	natur	6,6	7,5	5,0	100
054 0701 113 03	weiß	7,2	11,0	6,5	1000
054 0701 220 03	schwarz	7,2	11,0	6,5	1000
055 0070 000 03	natur	7,2	11,0	6,5	500
054 0702 600 03	weiß	7,2	12,0	6,5	500
054 0702 699 03	schwarz	7,2	12,0	6,5	500
054 0705 600 03	weiß	7,2	15,0	6,5	500
054 0705 699 03	schwarz	7,2	15,0	6,5	500
055 0073 000 03	natur	7,3	11,0	6,0	500
055 0075 000 03	natur	7,5	11,0	4,5	500
055 0080 000 03	natur	8,0	12,0	7,5	100
054 0802 600 03	weiß	8,0	12,0	7,5	500
054 0802 699 03	schwarz	8,0	12,0	7,5	500
054 0805 600 03	weiß	8,0	15,0	7,5	500
054 0805 699 03	schwarz	8,0	15,0	7,5	500
054 0852 113 03	weiß	8,5	12,0	8,0	500
054 0852 220 03	schwarz	8,5	12,0	8,0	500
055 0085 000 03	natur	8,5	12,0	8,0	100
054 0855 600 03	weiß	8,5	15,0	8,0	500
054 0855 699 03	schwarz	8,5	15,0	8,0	500
055 0088 000 03	natur	8,8	11,5	8,0	100
055 0093 000 03	natur	9,3	12,5	9,0	500
054 1003 113 03	weiß	10,0	12,0	4,0	500
054 1003 220 03	schwarz	10,0	12,0	4,0	500
055 0101 000 03	natur	10,0	12,0	4,0	100
054 1002 600 03	weiß	10,0	12,0	9,0	500
054 1002 699 03	schwarz	10,0	12,0	9,0	500
054 1005 600 03	weiß	10,0	15,0	9,0	500
054 1005 699 03	schwarz	10,0	15,0	9,0	500
055 0100 000 03	natur	10,0	15,0	9,0	100
055 0107 000 03	natur	10,7	14,8	9,0	100
055 0119 000 03	natur	11,9	14,8	8,0	500

## Dichtungsstopfen / Lochstopfen

Material: LD-PE (SK-03)

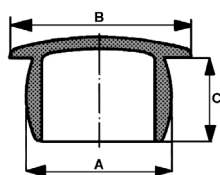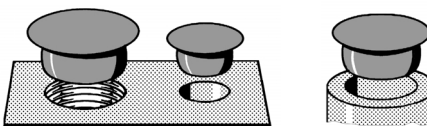

Artikel-Nr.	Farbe	Maße			MOQ Stück
		A	B	C	
054 1198 600 03	weiß	11,9	18,0	8,5	500
054 1198 699 03	schwarz	11,9	18,0	8,5	500
055 0125 000 03	natur	12,8	17,5	9,0	500
055 0132 000 03	natur	13,2	17,5	8,0	100
055 0136 000 03	natur	13,6	19,5	9,0	100
055 0143 000 03	natur	14,6	18,5	9,5	500
054 1549 113 03	weiß	15,4	19,0	8,5	500
054 1549 220 03	schwarz	15,4	19,0	8,5	500
054 1549 113 03	weiß	15,4	19,0	8,5	500
054 1549 220 03	schwarz	15,4	19,0	8,5	500
055 0154 000 03	natur	15,4	19,0	8,5	100
055 0157 000 03	natur	15,9	19,0	8,5	500
055 0168 000 03	natur	16,8	19,5	9,5	500
055 0172 000 03	natur	17,4	23,0	9,5	100
055 0183 000 03	natur	18,8	21,5	9,0	100
055 0196 000 03	natur	19,6	25,5	9,3	100
055 0200 000 03	natur	20,5	25,5	9,0	100
055 0210 000 03	natur	21,0	26,0	13,0	100
055 0223 000 03	natur	22,6	29,0	9,0	250
055 0230 000 03	natur	23,0	27,4	19,3	100
055 0240 000 03	natur	24,0	27,0	12,8	100
055 0245 000 03	natur	25,0	32,0	13,0	100
055 0255 000 03	natur	24,8	31,5	6,0	100
055 0261 000 03	natur	26,0	28,5	11,8	100
055 0260 000 03	natur	26,0	31,5	12,3	100
055 0272 000 03	natur	27,0	29,6	15,0	100
055 0286 000 03	natur	28,6	34,0	15,0	100
055 0312 000 03	natur	31,2	38,0	13,0	100
055 0335 000 03	natur	33,5	41,0	11,2	100
055 0340 000 03	natur	34,0	40,0	20,0	100
055 0356 000 03	natur	35,5	46,5	15,0	100
055 0365 000 03	natur	36,5	46,5	18,0	100
055 0395 000 03	natur	39,5	46,0	15,0	100
055 0420 000 03	natur	42,2	44,5	13,0	100
055 0433 000 03	natur	43,3	50,5	15,0	100
055 0455 000 03	natur	45,3	51,0	16,0	100
055 0458 000 03	natur	45,8	51,0	16,0	100
055 0505 000 03	natur	50,5	57,0	14,0	100
055 0520 000 03	natur	52,5	59,0	16,0	100
055 0553 000 03	natur	55,3	59,5	19,5	100
055 0555 000 03	natur	55,5	60,0	16,0	100
055 0580 000 03	natur	58,0	63,0	19,5	100
055 0615 000 03	natur	61,0	74,0	19,0	50
055 0700 000 03	natur	70,0	80,0	18,0	50
055 0850 000 03	natur	85,0	95,5	18,0	50
055 1100 000 03	natur	110,5	130,0	18,0	50