


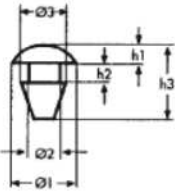























Einrastpuffer ohne Zapfen

Material: siehe Tabelle (VTD-93)

Farbe: schwarz



Artikel-Nr.	Material Shore A °	Maße			h1	h2	h3	MOQ Stück
		ø1	ø2	ø3				
 1244-01	EPDM 38	6,0	3,0	5,0	1,8	1,7	5,4	500
 1246-01	EPDM 50	6,0	3,0	5,0	2,1	2,2	7,6	500
 1350-01	EPDM 38	7,4	3,5	5,7	2,5	2,5	7,0	500
 1347-01	EPDM 50	7,5	4,0	5,0	4,1	6,3	12,6	500
 1346-01	EPDM 50	7,8	4,0	4,8	7,0	5,0	14,2	500
 1306-01	EPDM 62	9,0	4,5	5,5	1,0	2,2	7,5	500
 1308-01	EPDM 62	9,0	4,5	5,5	2,1	2,2	8,6	500
 1299-01	EPDM 50	9,0	5,0	7,0	5,0	1,5	13,6	500
 1310-01	EPDM 50	9,5	4,5	7,5	2,5	1,2	7,7	500
 1332-01	EPDM 62	9,5	5,8	8,0	2,7	2,0	7,0	500
 1303-01	EPDM 38	9,8	5,6	7,5	2,0	2,5	9,5	500
 1311-01	EPDM 62	9,8	5,6	7,5	3,0	2,5	10,5	500
 1309-01	EPDM 62	10,0	6,4	7,8	3,2	1,1	6,5	500
 1334-01	EPDM 62	11,7	7,8	10,0	4,5	2,0	9,4	500
 1313-01	EPDM 50	11,8	5,5	7,4	5,5	2,9	11,0	500
 1312-01	EPDM 62	12,0	5,0	6,5	2,0	2,0	6,0	500
 1314-01	EPDM 62	12,0	6,0	10,0	4,2	3,0	9,3	500
 1323-01	EPDM 50	12,0	5,5	7,3	5,5	5,0	13,1	500
 1319-01	EPDM 50	12,5	6,0	8,3	3,0	2,0	12,0	500
 1318-01	EPDM 62	13,0	7,0	9,0	3,0	1,5	9,7	500
 1298-01	EPDM 40	13,0	5,0	7,0	3,5	1,5	12,0	500
 1316-01	EPDM 62	14,0	7,5	10,0	5,0	1,5	11,1	500
 1315-01	EPDM 62	14,0	7,5	10,0	5,0	2,0	12,1	500
 1345-01	EPDM 62	15,0	10,2	13,0	5,0	1,5	9,6	500