
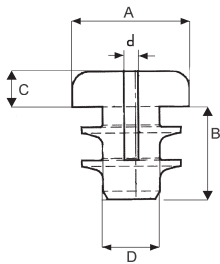


## Lamellenstopfen

Material: EPDM (VTD-93) 80 °Sh  
Farbe: schwarz  
Temperatur: -40 °C bis +130 °C


Ozon- und witterungsbeständig.

Auf Anfrage auch NBR (schwarz) (VTD-04)  
und Silikon (rotbraun) (VTD-06) lieferbar.

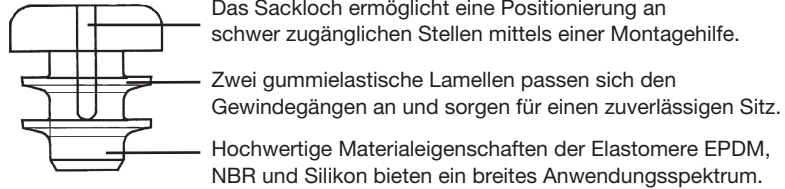

Artikel-Nr.	Durchmesser-Bereich	Maße					MOQ Stück
		A $\phi$	B	C	D	d	
1611-01	4,0 – 5,5	8,0	7,0	2,5	3,5	1,5	500
1612-01	5,5 – 7,0	9,0	7,0	2,8	4,5	1,5	500
1613-01	7,0 – 8,5	10,5	7,0	3,0	6,5	1,7	250
1614-01	8,5 – 10,0	12,0	7,0	3,0	7,5	2,0	500
1615-01	10,0 – 12,0	14,0	7,0	3,0	8,5	3,0	500
1616-01	12,0 – 16,0	18,0	9,8	4,0	10,6	4,0	250

Material: LD-PE (SK-03)  
Farbe: schwarz,  
weiß und grau  
auf Anfrage

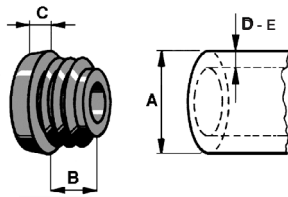






Artikel-Nr.	Maße					MOQ Stück
	A	B	C	D	E	
085 0100 699 03	10,0	12,0	3,5	1,5	2,0	100
085 0120 699 03	12,0	12,0	3,5	1,5	2,0	500
085 0130 699 03	13,0	12,0	4,0	0,8	2,0	100
085 0140 699 03	14,0	12,0	5,0	1,5	2,0	100
085 0150 699 03	15,0	12,0	3,0	0,8	2,0	500
085 0160 699 03	16,0	12,0	5,0	0,8	2,0	100
085 0180 699 03	18,0	12,0	5,0	0,8	2,0	100
085 0190 699 03	19,0	12,0	5,0	0,8	2,0	100
085 0200 699 03	20,0	12,0	5,0	0,8	2,5	100
085 0210 699 03	21,0	12,0	5,0	1,5	2,0	100
085 0220 699 03	22,0	12,0	5,0	1,0	3,0	100
085 0230 699 03	23,0	12,0	5,0	1,5	2,0	100
085 0240 699 03	24,0	12,0	5,0	1,5	2,0	100
085 0250 699 03	25,0	12,0	5,0	1,0	2,5	100
085 0260 699 03	26,0	12,0	5,0	1,5	2,0	100
085 0270 699 03	27,0	12,0	5,0	1,0	3,0	100
085 0280 699 03	28,0	12,0	5,0	0,8	2,5	100
085 0300 699 03	30,0	12,0	5,0	1,5	2,0	100
085 0320 699 03	32,0	12,0	5,0	0,8	2,5	100
085 0340 699 03	34,0	12,0	5,0	1,0	3,0	50
085 0350 699 03	35,0	12,0	5,0	1,0	2,5	50
085 0360 699 03	36,0	12,0	5,0	1,5	2,0	50
085 0370 699 03	37,0	12,0	5,0	1,5	2,0	50
085 0380 699 03	38,0	12,0	5,0	1,5	3,5	50
085 0400 699 03	40,0	12,0	5,0	1,0	3,0	50
085 0420 699 03	42,0	12,0	5,0	0,8	2,5	50
085 0430 699 03	43,0	12,0	5,0	2,0	2,5	50
085 0450 699 03	45,0	12,0	5,0	0,8	3,5	50
085 0490 699 03	48,0	12,0	5,0	1,2	3,6	50
085 0500 699 03	50,0	12,0	5,0	1,0	3,0	50
085 0550 699 03	55,0	12,0	5,0	1,0	3,0	50
085 0600 699 03	60,0	19,0	4,0	1,5	3,0	25

weitere Abmessungen sind auf Anfrage lieferbar

# Lamellenstopfen

Material: LD-PE (SK-03)

Farbe: schwarz  
weiß und grau auf Anfrage

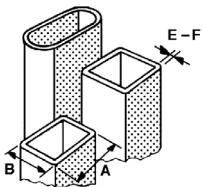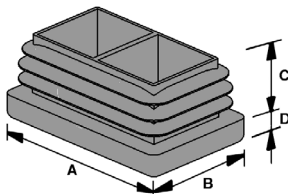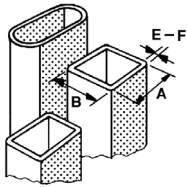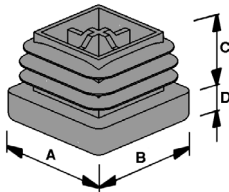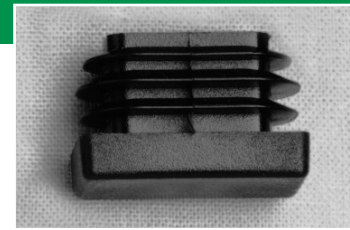

Artikel-Nr.	Maße						MOQ Stück
	A	B	C	D	E	F	
056 0100 699 03	10,0	10,0	11,5	4,0	1,5	2,0	500
056 0120 699 03	12,0	12,0	7,0	2,0	1,0	2,0	500
056 0130 699 03	13,0	13,0	11,5	4,0	1,5	2,0	100
056 0150 699 03	15,0	15,0	13,0	3,0	1,0	2,0	500
056 0160 699 03	16,0	16,0	11,5	5,0	1,5	2,0	500
056 0180 699 03	18,0	18,0	12,0	5,0	1,0	2,0	500
056 0200 699 03	20,0	20,0	11,5	5,0	1,5	2,0	100
056 0220 699 03	22,0	22,0	11,5	5,0	1,0	3,5	100
056 0250 699 03	25,0	25,0	12,0	6,0	1,5	2,0	100
056 0300 699 03	30,0	30,0	12,0	6,0	1,5	2,0	100
056 0350 699 03	35,0	35,0	14,5	5,0	1,0	3,0	50
056 0400 699 03	40,0	40,0	14,5	5,0	1,5	3,0	50
056 0450 699 03	45,0	45,0	14,5	5,0	1,0	3,0	50
056 0500 699 03	50,0	50,0	20,0	5,0	1,5	4,0	50
056 0600 699 03	60,0	60,0	24,0	5,0	1,5	3,5	10
056 0800 699 03	80,0	80,0	24,0	8,0	3,0	5,0	10
056 0900 699 03	90,0	90,0	25,0	7,0	3,5	5,0	10
056 1000 699 03	100,0	100,0	24,0	7,0	1,0	4,0	10

Artikel-Nr.	Maße						MOQ Stück
	A	B	C	D	E	F	
057 2010 699 03	20,0	10,0	11,5	3,0	1,0	2,0	100
057 2012 699 03	20,0	12,0	9,5	2,0	1,0	1,5	100
057 2015 699 03	20,0	15,0	11,5	5,0	1,0	1,5	100
057 2016 699 03	20,0	16,0	11,5	5,0	1,5	2,0	100
057 2510 699 03	25,0	10,0	11,5	4,0	1,5	2,0	100
057 2515 699 03	25,0	15,0	11,5	5,0	1,0	2,5	100
057 2520 699 03	25,0	20,0	11,5	5,0	1,5	2,0	100
057 3010 699 03	30,0	10,0	11,5	4,0	1,5	2,0	100
057 3015 699 03	30,0	15,0	12,0	5,0	1,0	2,0	100
057 3020 699 03	30,0	20,0	12,0	6,0	1,0	2,0	100
057 3520 699 03	35,0	20,0	11,5	5,0	1,5	2,5	100
057 3525 699 03	35,0	25,0	11,5	5,0	1,5	2,0	100
057 4020 699 03	40,0	20,0	14,5	6,0	1,5	2,0	100
057 4025 699 03	40,0	25,0	11,5	5,0	1,0	3,0	100
057 4030 699 03	40,0	30,0	11,5	5,0	1,0	3,0	100
057 4520 699 03	45,0	20,0	11,5	5,0	1,5	2,0	100
057 4525 699 03	45,0	25,0	11,5	5,0	1,5	2,0	50
057 5020 699 03	50,0	20,0	14,5	5,0	1,0	3,0	50
057 5025 699 03	50,0	25,0	14,5	5,0	1,0	3,0	50
057 5030 699 03	50,0	30,0	14,5	5,0	1,0	3,0	50
057 6020 699 03	60,0	20,0	14,5	5,0	1,5	2,0	25
057 6025 699 03	60,0	25,0	14,5	5,0	1,0	2,5	25
057 6030 699 03	60,0	30,0	14,5	5,0	1,0	2,5	25
057 6040 699 03	60,0	40,0	14,5	5,0	1,0	3,0	25
057 8040 699 03	80,0	40,0	14,5	5,0	1,0	3,0	10
057 9030 699 03	120,0	30,0	14,5	5,0	1,5	2,0	10

weitere Abmessungen sind auf Anfrage lieferbar