

# Kontaktteile

# Pièces de raccord

# Contacts

Werkstoff:

BZ = Bronze  
MS = Messing

Matière:

BZ = bronze  
MS = laiton

Material:

BZ = bronze  
MS = brass

Oberflächenbehandlung: Code

bl = blank (0)  
ag = versilbert (1)  
au = vergoldet (2)  
ni = vernickelt (5)  
sn = verzinkt (8)

Traitements de surface: Code

bl = brut (0)  
ag = argenté (1)  
au = doré (2)  
ni = nickelé (5)  
sn = étamé (8)

Surface-plating: Code

bl = clean (0)  
ag = silver-plated (1)  
au = gold-plated (2)  
ni = nickel-plated (5)  
sn = tin-plated (8)

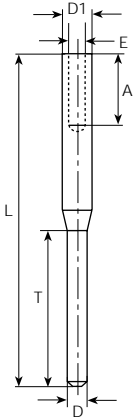


 
 
 
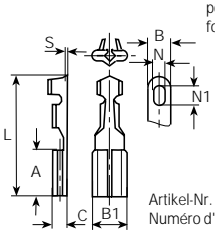
 
 
 
 
 
Bestellbeispiel:

Exemple de commande:

Example of order:

1368.68

(1368 MS sn)

	Ø 1.3	Ø 2.0	für Stecker pour fiche for plug		Ø 0.9	Ø 1.0	
 <p>Artikel-Nr. Numéro d'article Part-No. →</p> <p>Print Bohrung Trou Hole →</p> <p>Stand.-Packg.</p> <p>Werkzeuge Outils / Tools</p>	 <p>1368.6( ) MS</p> <p>Ø 1.3 T 10 L 22 D Ø 1.3 D1 Ø 2 A 5 E Ø 1.1 500</p>	 <p>1369.6( ) MS</p> <p>Ø 2 T 11.5 L 24 D Ø 2 D1 Ø 4 A 10 E Ø 3.2 200</p>			 <p>1349.6( ) MS</p> <p>Ø 0.8 T 3.2 L 9.2 A 5 B2 1.4 B1 Ø 1.8 B 0.8 S 0.25 1000</p>	 <p>1345.2( ) BZ</p> <p>Ø 1.3 T 5 L 15 A 5.9 B2 2.6 B1 Ø 2.6 B 1.3 S 0.3 1000</p>	 <p>1346.2( ) BZ</p> <p>Ø 1.1 T 4.5 L 11 A 5.9 B2 2 B1 Ø 2.6 B 1 S 0.3 1000</p>
 <p>für Stecker pour fiche for plug</p> <p>Artikel-Nr. Numéro d'article Part-No. →</p> <p>Stand.-Packg.</p> <p>Werkzeuge Outils / Tools</p>	 <p>1344.2( ) BZ 1344.6( ) MS</p> <p>A 5.9 L 16 C 2.6 B1 2.6 B 2.6 N 1.3 N1 4 S 0.3 2000</p>	 <p>1344A.2( ) BZ</p> <p>A 6.5 L 15 C 2 B1 1.9 B 2 N 1 N1 3 S 0.3 2000</p>	 <p>1361.6( ) MS</p> <p>A 5.5 L 13.5 C 2.2 B1 3.8 B - mm<sup>2</sup> 0.3-0.5 N1 - S 0.25 1000</p>	 <p>1360.2( ) BZ</p> <p>A 5.5 L 13.5 C 2.2 B1 3.8 B 2.5 N 1.2 N1 2.2 S 0.25 1000</p>	 <p>1346B.2( ) BZ</p> <p>A 7.2 L 18 C 2.2 B1 2.4 B 2.5 N 1.3 N1 3.2 S 0.3 1000</p>		