


### SILVYN® LGF-2-M

### SILVYN® LGS-2-M

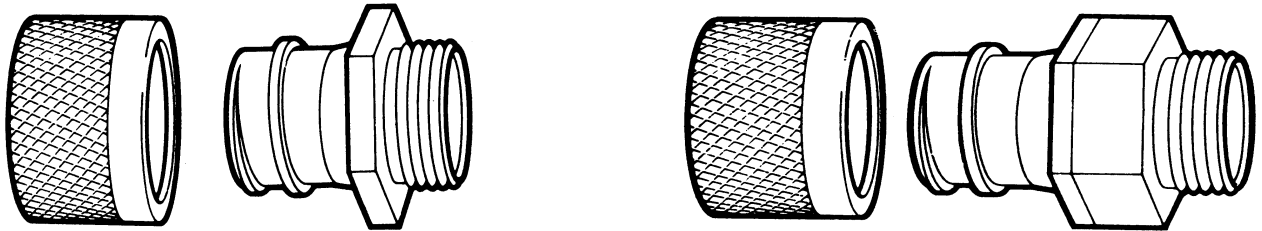

Größe	Schlüsselweite		Gewindelänge		Gesamtlänge		Bohrung	
	LGF 2 M	LGS 2 M	LGF 2 M	LGS 2 M	LGF 2 M	LGS 2 M	LGF 2 M	LGS 2 M
<b>M12x1,5</b>	13	13	8,0	8,0	21,0	30,2	5,6	5,6
<b>M16x1,5</b>	17	17	8,0	8,0	23,0	32,2	8,5	8,5
<b>M16x1,5</b>	19	22	10,0	10,0	25,0	34,2	11,5	11,5
<b>M20x1,5</b>	22	22	10,0	10,0	25,0	34,2	11,5	11,5
<b>M20x1,5</b>	24	24	10,0	10,0	26,3	35,5	15,3	15,3
<b>M25x1,5</b>	29	29	12,0	12,0	32,5	43,7	19,1	19,1
<b>M32x1,5</b>	38	38	13,0	13,0	36,8	48,0	26,2	26,2
<b>M40x1,5</b>	48	48	14,0	14,0	39,0	51,2	34,2	34,2
<b>M50x1,5</b>	58	58	15,0	15,0	42,0	54,2	44,8	44,8
<b>M63x1,5</b>	70	70	18,0	18,0	50,0	63,2	54,5	54,5
<b>M75x1,5</b>	84	84	20,0	20,0	60,0	74,2	66,5	66,5

**Material:** Messing vernickelt

**Anwendung:** Metallschutzschlauch SILVYN® LCC-2

**Zuordnung:** SILVYN® LGF-M 16 (oder LGS-M 16) passend zu SILVYN® LCC-2/ 16  
SILVYN® LGF-M 20 (oder LGS-M 20) passend zu SILVYN® LCC-2/ 20, etc.

**Aufbau:** SILVYN® LGF-M feste Metallverschraubung  
SILVYN® LGS-M drehbare Metallverschraubung