




Artikel-Nr.: 530293

Bez.: SAP/FME-Kupplung, Crimpausführung, RG 174/U

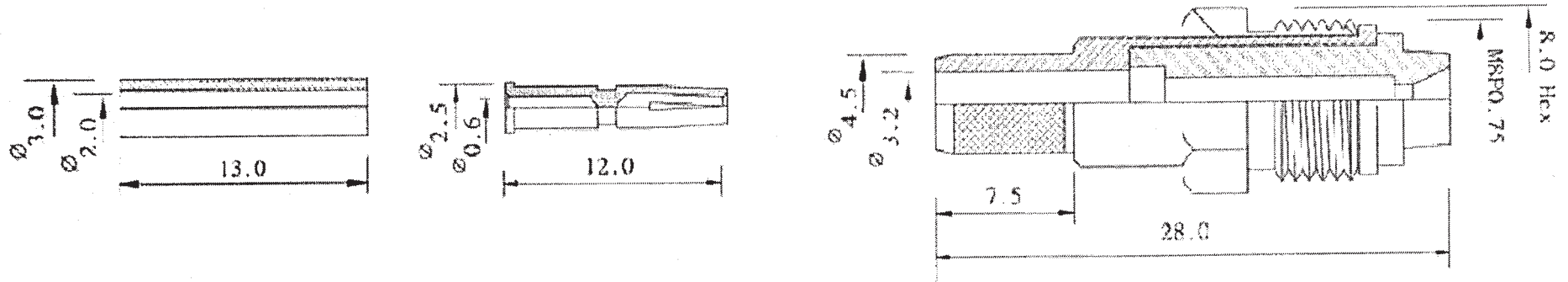

Impedance	50 Ω
Frequency range	0.1 GHz
VSWR (straight connector)	≤ 1.22 (100)
Insulation resistance	$\geq 5 \times 10^4 \Omega$
Center contact resistance	$\leq 10 \text{ m}\Omega$
Outer contact resistance	$\leq 10 \text{ m}\Omega$
Test voltage	1000V rms
Working voltage	500V rms
Insertion loss(dB)	≤ 0.1 dB max @ 100 MHz

No.	DESCRIPTION	MATERIAL	FINISH
1	BODY	BRASS	NICKEL
2	CONTACT	BRASS	GOLD
3	INSULATOR	TEFLON	WHITE
4	FERRULE	BRASS	NICKEL
5	SUPPORT	DELFIN	WHITE
6	NUT	BRASS	NICKEL

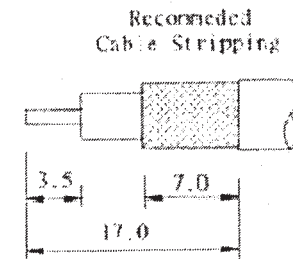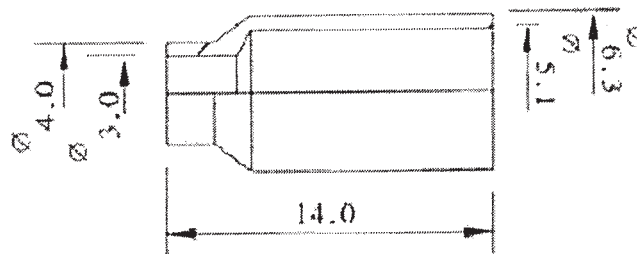

www.bkl-electronic.de

Technische Änderungen vorbehalten. Ausführungen können variieren. Sollten Sie ein Muster benötigen kontaktieren Sie uns bitte.

BKL-ELECTRONIC Kreimendahl GmbH • Märkenstück 14 • 58509 Lüdenscheid
Tel: +49 (0)2351-3621-0 • Fax: +49 (0)2351-3621-29 • info@bkl-electronic.de

