






## Locknuts, metric

## Gegenmuttern, metrisch

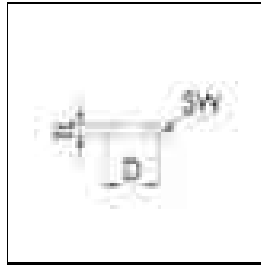

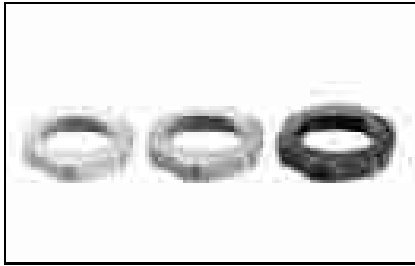

 
**Temperature range:** -40°C to 100°C, intermittently to approx. 150°C  
**Material:** Polyamide / reinforced glass fibre

**Einsatztemperatur:** -40°C bis 100°C, kurzzeitig bis ca. 150°C  
**Material:** Polyamid / glasfaserverstärkt

| Type    | WISKA-No.<br>RAL 7035<br>□ 100. | WISKA-No.<br>RAL 9005<br>■ 100. | WISKA-No.<br>RAL 7001<br>■ 100. |  | <br>mm | <br>mm | TL<br>mm |
|---------|---------------------------------|---------------------------------|---------------------------------|---|---|---|----------|
| EMUG 12 | 60770                           | 61780                           | 62712                           | 100/1000  | M 12x1,5  | 18  | 5        |
| EMUG 16 | 60771                           | 61781                           | 62713                           | 100/1000  | M 16x1,5  | 22  | 5        |
| EMUG 20 | 60772                           | 61782                           | 62714                           | 100/1000  | M 20x1,5  | 27  | 5        |
| EMUG 25 | 60773                           | 61783                           | 62715                           | 100   | M 25x1,5  | 32  | 6        |
| EMUG 32 | 60774                           | 61784                           | 62716                           | 100   | M 32x1,5  | 40  | 6        |
| EMUG 40 | 60775                           | 61785                           | 62717                           | 50  | M 40x1,5  | 50  | 7        |
| EMUG 50 | 60776                           | 61786                           | 62718                           | 25  | M 50x1,5  | 60  | 7        |
| EMUG 63 | 60777                           | 61787                           | 62719                           | 10  | M 63x1,5  | 75  | 7        |

## Locknuts, PG

## Gegenmuttern, PG

| Type     | WISKA-No.<br>RAL 7035<br>□ 100. | WISKA-No.<br>RAL 9005<br>■ 100. |  | <br>mm | <br>mm | TL<br>mm |
|----------|---------------------------------|---------------------------------|---|---|---|----------|
| MUG 7    | 60670                           | 60680                           | 100/1000  | PG 7  | 19  | 5        |
| MUG 9    | 60671                           | 60681                           | 100/1000  | PG 9  | 22  | 5        |
| MUG 11   | 60672                           | 60682                           | 100/1000  | PG 11   | 24  | 5        |
| MUG 13,5 | 60673                           | 60683                           | 100/1000  | PG 13,5   | 27  | 6        |
| MUG 16   | 60674                           | 60684                           | 100/1000  | PG 16   | 30  | 6        |
| MUG 21   | 60675                           | 60685                           | 100/1000  | PG 21   | 36  | 7        |
| MUG 29   | 60676                           | 60686                           | 50  | PG 29   | 46  | 7        |
| MUG 36   | 60677                           | 60687                           | 25  | PG 36   | 60  | 8        |
| MUG 42   | 60678                           | 60688                           | 25  | PG 42   | 73  | 8        |
| MUG 48   | 60679                           | 60689                           | 10  | PG 48   | 78  | 8        |