

Inhalt / contents: 100 St./ pcs


10 x 160 mA
 10 x 250 mA
 10 x 500 mA
 10 x 630 mA
 10 x 800 mA
 10 x 1 A
 10 x 1,6 A
 10 x 2,5 A
 10 x 4 A
 10 x 6,3 A

5 x 20 mm

F = (DIN 41661 / EN 60127-2-2)
 M = (DIN 41571/2)
 T = (DIN 41662 / EN 60127-2-3)

Bestell / Order Nr.:

F 120.900
M 121.800
T 122.800

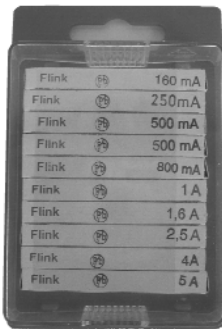

Inhalt / contents: 100 St./ pcs

F	T
10 x 160 mA	10 x 160 mA
10 x 250 mA	10 x 250 mA
20 x 500 mA	20 x 500 mA
10 x 800 mA	10 x 800 mA
10 x 1 A	10 x 1,25 mA
10 x 1,6 A	10 x 1,6 A
10 x 2,5 A	10 x 2,5 A
10 x 4 A	10 x 4 A
10 x 5 A	10 x 6,3 A

5 x 20 mm

F = (DIN 41.660 / EN 60127-2-1)
 T = (EN 60127-2-5)

Bestell / Order Nr.:

F 120.950
T 122.850



Inhalt / contents: 200 St./ pcs

10 x 100 mA	30 x 1 A
10 x 200 mA	10 x 1,25 A
10 x 315 mA	20 x 1,6 A
10 x 400 mA	10 x 2,5 A
30 x 500 mA	10 x 4 A
20 x 630 mA	10 x 6,3 A
20 x 800 mA	

5 x 20 mm

F = (DIN 41661 / EN 60127-2-2)
 M = (DIN 41571/2)
 T = (DIN 41662 / EN 60127-2-3)

Bestell / Order Nr.:

F 520.800
M 521.800
T 522.800



Inhalt / contents: 360 St./ pcs

20 x 100 mA	20 x 1 A
20 x 125 mA	20 x 1,25 A
20 x 160 mA	20 x 1,6 A
20 x 200 mA	20 x 2 A
20 x 250 mA	20 x 2,5 A
20 x 315 mA	20 x 3,15 A
20 x 400 mA	20 x 4 A
20 x 500 mA	20 x 6,3 A
20 x 630 mA	
20 x 800 mA	

5 x 20 mm

F = (DIN 41661 / EN 60127-2-2)
 M = (DIN 41571/2)
 T = (DIN 41662 / EN 60127-2-3)

Bestell / Order Nr.:

F E3520.800
M E3521.800
T E3522.800