

---

## Gas-Überspannungsableiter

---


**Typ: BB-S;** D=8mm, L=6,05mm;  $U_{agN} \leq 230V$ : 10kA/10A;  $U_{agN} > 230V$ : 5kA/5A; bedrahtet.

**Conrad 532837 ESKA 610.150S**



**Typ: BH-S**; D=8mm, L=6,05mm;  $U_{agN} \leq 230V$ : 20kA/20A;  
 $U_{agN} = 350/600V$ : 10kA/10A;  $U_{agN} > 600V$ : 5kA/5A; bedrahtet.

**ESKA 620.230S**

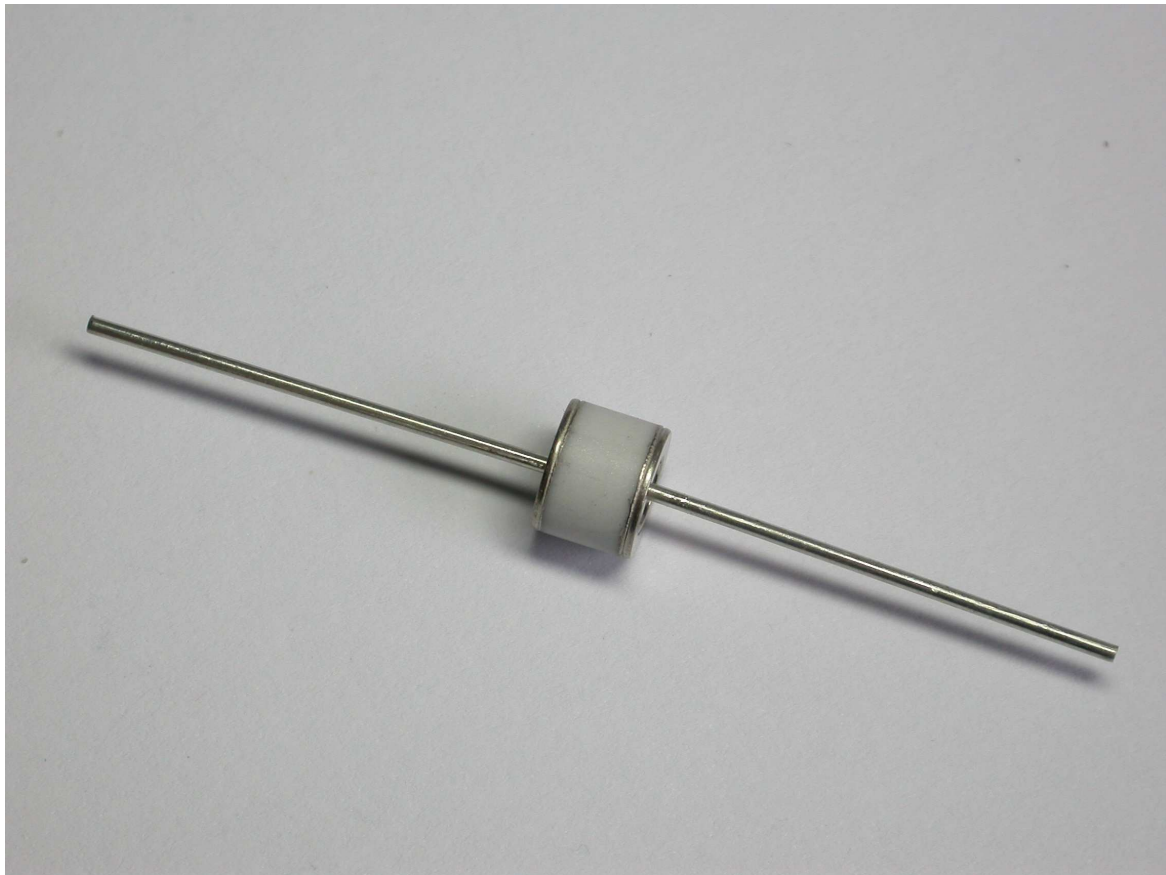

**Typ: BT-S**; D=8,25mm, L=9,1mm;  $U_{agN} \leq 350V$ : 20kA/20A;  $U_{agN} > 350V$ : 10kA/10A; Mittelelektrode; für Printmontage.

**ESKA 680.090S**

