
Gas-Überspannungsableiter


Typ: BB-S; D=8mm, L=6,05mm; $U_{agN} \leq 230V$: 10kA/10A; $U_{agN} > 230V$: 5kA/5A; bedrahtet.

Conrad 532837 ESKA 610.150S



Typ: BH-S; D=8mm, L=6,05mm; $U_{agN} \leq 230V$: 20kA/20A;
 $U_{agN} = 350/600V$: 10kA/10A; $U_{agN} > 600V$: 5kA/5A; bedrahtet.

ESKA 620.230S

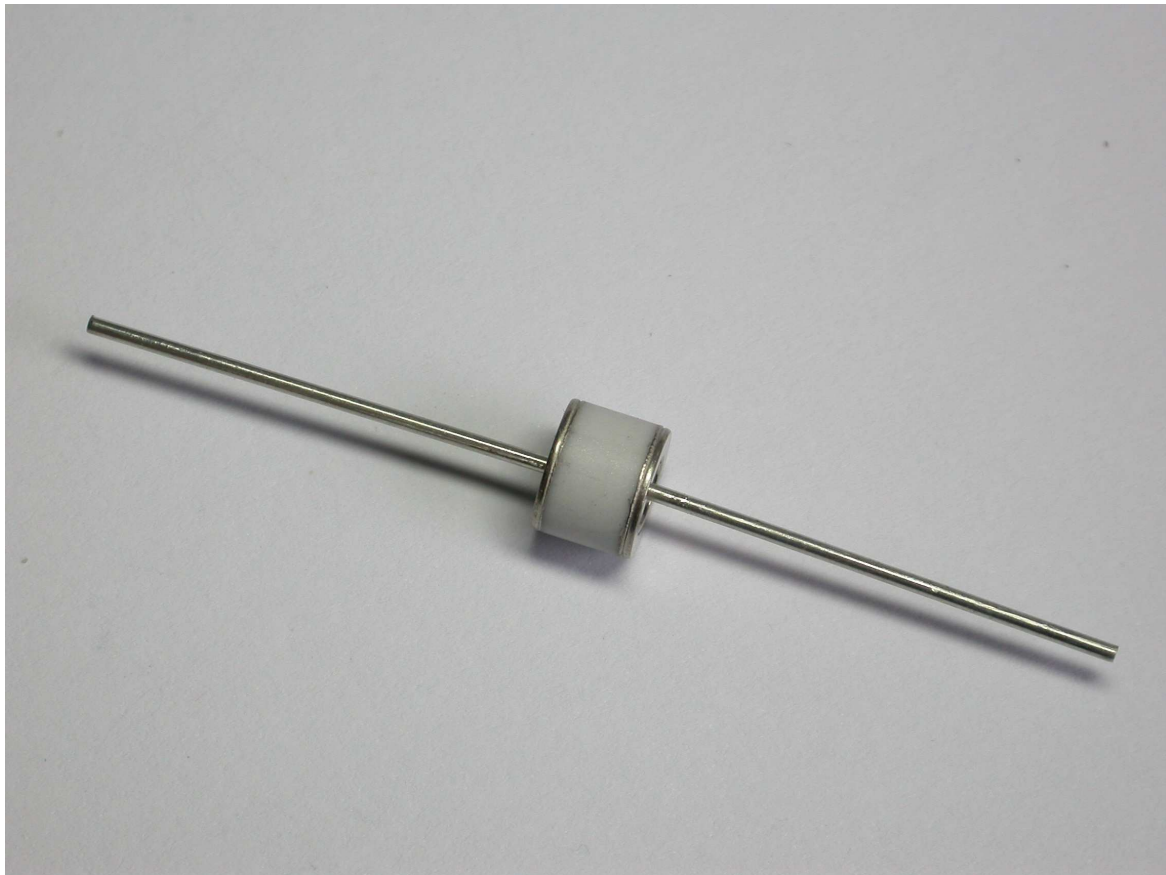

Typ: BT-S; D=8,25mm, L=9,1mm; $U_{agN} \leq 350V$: 20kA/20A; $U_{agN} > 350V$: 10kA/10A; Mittelelektrode; für Printmontage.

ESKA 680.090S

