
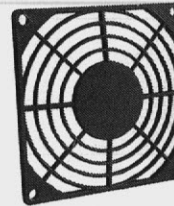


Maße	Art.-Nr.	EAN	V	rpm	m³/h	W	A	dB(A)	passende Schutzgitter		
									verzinkt	Kunststoff	Kunststoff mit Filtereinlage
25 x 25 x 10	N40960	4046293409607	5	10.000	5,1	0,43	0,085	16			
25 x 25 x 10	N40962	4046293409621	12	10.000	5,1	0,45	0,037	16			
40 x 40 x 20	N40961	4046293409614	5	6.200	13,09	0,7	0,14	21	x		
40 x 40 x 20	N40963	4046293409638	12	6.200	13,09	0,76	0,063	21	x		
60 x 60 x 25	N40964	4046293409645	12	4.500	39,95	1,88	0,156	33,5	x	x	x
60 x 60 x 25	N40969	4046293409690	24	4.500	39,95	2,09	0,087	33,5	x	x	x
80 x 80 x 25	N40965	4046293409652	12	3.200	69,7	1,7	0,145	33	x	x	x
80 x 80 x 25	N40970	4046293409706	24	3.200	69,7	1,8	0,073	33	x	x	x
92 x 92 x 25	N40966	4046293409669	12	3.000	87,6	2,0	0,165	34	x	x	x
120 x 120 x 25	N40967	4046293409676	12	2.200	127,5	1,9	0,161	34	x	x	x

### passende Schutzgitter

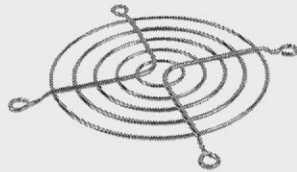

Maße
40 x 40 x 20
60 x 60 x 25
80 x 80 x 25
92 x 92 x 25
120 x 120 x 25

verzinkt	
Art.-Nr.	EAN
N40971	4046293409713
N40972	4046293409720
N40973	4046293409737
N40974	4046293409744
N40975	4046293409751

Kunststoff	
Art.-Nr.	EAN
N40980	4046293409805
N40981	4046293409812
N40982	4046293409829
N40983	4046293409836

Kunststoff mit Filtereinlage	
Art.-Nr.	EAN
N40976	4046293409768
N40977	4046293409775
N40978	4046293409782
N40979	4046293409799