
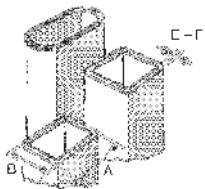
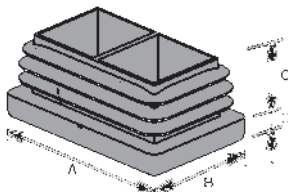
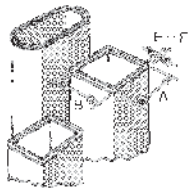
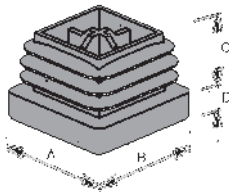


# Lamellenstopfen

Material: LD-PE (SK-03)

Farbe: schwarz  
weiß und grau auf Anfrage

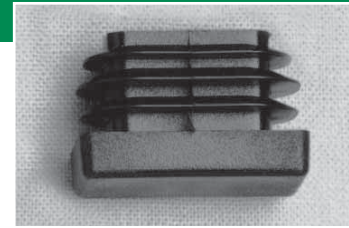

Artikel-Nr.	Maße						MOQ Stück
	A	B	C	D	E	F	
056 0100 699 03	10,0	10,0	11,5	4,0	1,5	2,0	500
056 0120 699 03	12,0	12,0	7,0	2,0	1,0	2,0	500
056 0130 699 03	13,0	13,0	11,5	4,0	1,5	2,0	100
056 0150 699 03	15,0	15,0	13,0	3,0	1,0	2,0	500
056 0160 699 03	16,0	16,0	11,5	5,0	1,5	2,0	500
056 0180 699 03	18,0	18,0	12,0	5,0	1,0	2,0	500
056 0200 699 03	20,0	20,0	11,5	5,0	1,5	2,0	100
056 0220 699 03	22,0	22,0	11,5	5,0	1,0	3,5	100
056 0250 699 03	25,0	25,0	12,0	6,0	1,5	2,0	100
056 0300 699 03	30,0	30,0	12,0	6,0	1,5	2,0	100
056 0350 699 03	35,0	35,0	14,5	5,0	1,0	3,0	50
056 0400 699 03	40,0	40,0	14,5	5,0	1,5	3,0	50
056 0450 699 03	45,0	45,0	14,5	5,0	1,0	3,0	50
056 0500 699 03	50,0	50,0	20,0	5,0	1,5	4,0	50
056 0600 699 03	60,0	60,0	24,0	5,0	1,5	3,5	10
056 0800 699 03	80,0	80,0	24,0	8,0	3,0	5,0	10
056 0900 699 03	90,0	90,0	25,0	7,0	3,5	5,0	10
056 1000 699 03	100,0	100,0	24,0	7,0	1,0	4,0	10

Artikel-Nr.	Maße						MOQ Stück
	A	B	C	D	E	F	
057 2010 699 03	20,0	10,0	11,5	3,0	1,0	2,0	100
057 2012 699 03	20,0	12,0	9,5	2,0	1,0	1,5	100
057 2015 699 03	20,0	15,0	11,5	5,0	1,0	1,5	100
057 2016 699 03	20,0	16,0	11,5	5,0	1,5	2,0	100
057 2510 699 03	25,0	10,0	11,5	4,0	1,5	2,0	100
057 2515 699 03	25,0	15,0	11,5	5,0	1,0	2,5	100
057 2520 699 03	25,0	20,0	11,5	5,0	1,5	2,0	100
057 3010 699 03	30,0	10,0	11,5	4,0	1,5	2,0	100
057 3015 699 03	30,0	15,0	12,0	5,0	1,0	2,0	100
057 3020 699 03	30,0	20,0	12,0	6,0	1,0	2,0	100
057 3520 699 03	35,0	20,0	11,5	5,0	1,5	2,5	100
057 3525 699 03	35,0	25,0	11,5	5,0	1,5	2,0	100
057 4020 699 03	40,0	20,0	14,5	6,0	1,5	2,0	100
057 4025 699 03	40,0	25,0	11,5	5,0	1,0	3,0	100
057 4030 699 03	40,0	30,0	11,5	5,0	1,0	3,0	100
057 4520 699 03	45,0	20,0	11,5	5,0	1,5	2,0	100
057 4525 699 03	45,0	25,0	11,5	5,0	1,5	2,0	50
057 5020 699 03	50,0	20,0	14,5	5,0	1,0	3,0	50
057 5025 699 03	50,0	25,0	14,5	5,0	1,0	3,0	50
057 5030 699 03	50,0	30,0	14,5	5,0	1,0	3,0	50
057 6020 699 03	60,0	20,0	14,5	5,0	1,5	2,0	25
057 6025 699 03	60,0	25,0	14,5	5,0	1,0	2,5	25
057 6030 699 03	60,0	30,0	14,5	5,0	1,0	2,5	25
057 6040 699 03	60,0	40,0	14,5	5,0	1,0	3,0	25
057 8040 699 03	80,0	40,0	14,5	5,0	1,0	3,0	10
057 9030 699 03	120,0	30,0	14,5	5,0	1,5	2,0	10

weitere Abmessungen sind auf Anfrage lieferbar