 



Bumper Elastikpuffer / Gehäusefüße



Material: Polyurethan (BSI)
Farbe: s. Tabelle





| halbrund | Artikel-Nr. | Farbe | Maße | | VPE Stück | Karton Stück | MOQ Stück |
|----------|-------------|-------|------|---|-----------|--------------|-----------|
| | | | A | B | | | |

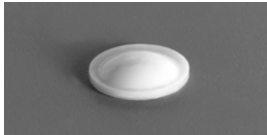



| | | | | | | |
|------------|---------|-----|-----|-----|--------|--------|
| BS-40-CL-R | klar | 6,4 | 1,6 | 272 | 11.424 | 272 |
| BS-40-BK-R | schwarz | 6,4 | 1,6 | 272 | 11.424 | 272 |
| BS-40-WH-R | weiß | 6,4 | 1,6 | 272 | 11.424 | 11.424 |

 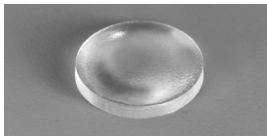



| | | | | | | |
|------------|---------|-----|-----|-----|-------|-----|
| BS-25-CL-R | klar | 6,4 | 2,1 | 450 | 5.400 | 450 |
| BS-25-BK-R | schwarz | 6,4 | 2,1 | 450 | 5.400 | 450 |

 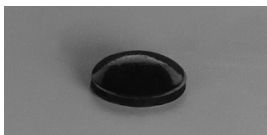


| | | | | | | |
|------------|---------|-----|-----|-----|-------|-----|
| BS-27-CL-R | klar | 7,9 | 2,2 | 450 | 5.400 | 450 |
| BS-27-BK-R | schwarz | 7,9 | 2,2 | 450 | 5.400 | 450 |

 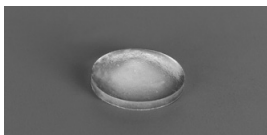



| | | | | | | |
|------------|---------|-----|-----|-----|-------|-------|
| BS-07-CL-R | klar | 8,5 | 2,2 | 144 | 5.040 | 144 |
| BS-07-BK-R | schwarz | 8,5 | 2,2 | 144 | 5.040 | 5.040 |
| BS-07-WH-R | weiß | 8,5 | 2,2 | 144 | 5.040 | 5.040 |

 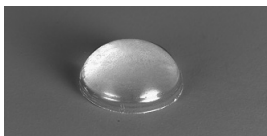


| | | | | | | |
|------------|---------|-----|-----|----|-------|-------|
| BS-12-CL-R | klar | 9,5 | 3,8 | 72 | 7.200 | 72 |
| BS-12-BK-R | schwarz | 9,5 | 3,8 | 72 | 7.200 | 72 |
| BS-12-GR-R | grau | 9,5 | 3,8 | 72 | 7.200 | 7.200 |
| BS-12-WH-R | weiß | 9,5 | 3,8 | 72 | 7.200 | 7.200 |
| BS-12-BR-R | braun | 9,5 | 3,8 | 72 | 7.200 | 7.200 |

 


| | | | | | | |
|------------|---------|-----|-----|-----|-------|-----|
| BS-22-CL-R | klar | 9,5 | 5,4 | 300 | 6.000 | 300 |
| BS-22-BK-R | schwarz | 9,5 | 5,4 | 300 | 6.000 | 300 |

 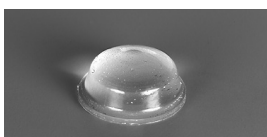


| | | | | | | |
|------------|---------|------|-----|-----|-------|-------|
| BS-02-CL-R | klar | 11,1 | 5,1 | 242 | 5.082 | 242 |
| BS-02-BK-R | schwarz | 11,1 | 5,1 | 242 | 5.082 | 242 |
| BS-02-GR-R | grau | 11,1 | 5,1 | 242 | 5.082 | 5.082 |
| BS-02-WH-R | weiß | 11,1 | 5,1 | 242 | 5.082 | 5.082 |
| BS-02-BR-R | braun | 11,1 | 5,1 | 242 | 5.082 | 5.082 |

 

| | | | | | | |
|------------|---------|------|-----|-----|-------|-------|
| BS-15-CL-R | klar | 15,7 | 7,9 | 128 | 3.200 | 128 |
| BS-15-BK-R | schwarz | 15,7 | 7,9 | 128 | 3.200 | 128 |
| BS-15-GR-R | grau | 15,7 | 7,9 | 128 | 3.200 | 3.200 |
| BS-15-WH-R | weiß | 15,7 | 7,9 | 128 | 3.200 | 3.200 |
| BS-15-BR-R | braun | 15,7 | 7,9 | 128 | 3.200 | 3.200 |

 

| | | | | | | |
|------------|---------|------|-----|----|-------|-------|
| BS-08-CL-R | klar | 17,8 | 9,6 | 98 | 2.254 | 98 |
| BS-08-BK-R | schwarz | 17,8 | 9,6 | 98 | 2.254 | 98 |
| BS-08-GR-R | grau | 17,8 | 9,6 | 98 | 2.254 | 2.254 |
| BS-08-WH-R | weiß | 17,8 | 9,6 | 98 | 2.254 | 2.254 |

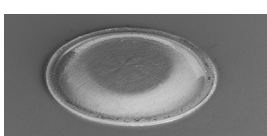

| | | | | | | |
|------------|---------|------|-----|----|-------|----|
| BS-39-CL-R | klar | 19,1 | 1,9 | 84 | 5.040 | 84 |
| BS-39-BK-R | schwarz | 19,1 | 1,9 | 84 | 5.040 | 84 |