 



**Bumper** Elastikpuffer / Gehäusefüße



Material: Polyurethan (BSI)  
Farbe: s. Tabelle





halbrund	Artikel-Nr.	Farbe	Maße		VPE Stück	Karton Stück	MOQ Stück
			A	B			

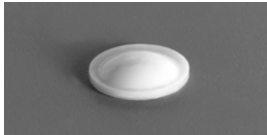



BS-40-CL-R	klar	6,4	1,6	272	11.424	272
BS-40-BK-R	schwarz	6,4	1,6	272	11.424	272
BS-40-WH-R	weiß	6,4	1,6	272	11.424	11.424

 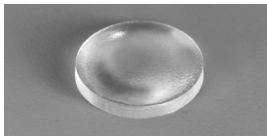



BS-25-CL-R	klar	6,4	2,1	450	5.400	450
BS-25-BK-R	schwarz	6,4	2,1	450	5.400	450

 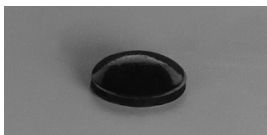


BS-27-CL-R	klar	7,9	2,2	450	5.400	450
BS-27-BK-R	schwarz	7,9	2,2	450	5.400	450

 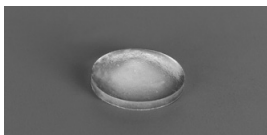



BS-07-CL-R	klar	8,5	2,2	144	5.040	144
BS-07-BK-R	schwarz	8,5	2,2	144	5.040	5.040
BS-07-WH-R	weiß	8,5	2,2	144	5.040	5.040

 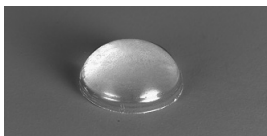


BS-12-CL-R	klar	9,5	3,8	72	7.200	72
BS-12-BK-R	schwarz	9,5	3,8	72	7.200	72
BS-12-GR-R	grau	9,5	3,8	72	7.200	7.200
BS-12-WH-R	weiß	9,5	3,8	72	7.200	7.200
BS-12-BR-R	braun	9,5	3,8	72	7.200	7.200

 


BS-22-CL-R	klar	9,5	5,4	300	6.000	300
BS-22-BK-R	schwarz	9,5	5,4	300	6.000	300

 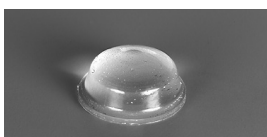


BS-02-CL-R	klar	11,1	5,1	242	5.082	242
BS-02-BK-R	schwarz	11,1	5,1	242	5.082	242
BS-02-GR-R	grau	11,1	5,1	242	5.082	5.082
BS-02-WH-R	weiß	11,1	5,1	242	5.082	5.082
BS-02-BR-R	braun	11,1	5,1	242	5.082	5.082

 

BS-15-CL-R	klar	15,7	7,9	128	3.200	128
BS-15-BK-R	schwarz	15,7	7,9	128	3.200	128
BS-15-GR-R	grau	15,7	7,9	128	3.200	3.200
BS-15-WH-R	weiß	15,7	7,9	128	3.200	3.200
BS-15-BR-R	braun	15,7	7,9	128	3.200	3.200

 

BS-08-CL-R	klar	17,8	9,6	98	2.254	98
BS-08-BK-R	schwarz	17,8	9,6	98	2.254	98
BS-08-GR-R	grau	17,8	9,6	98	2.254	2.254
BS-08-WH-R	weiß	17,8	9,6	98	2.254	2.254

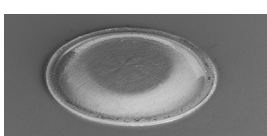

BS-39-CL-R	klar	19,1	1,9	84	5.040	84
BS-39-BK-R	schwarz	19,1	1,9	84	5.040	84