

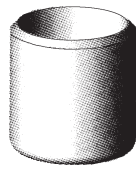
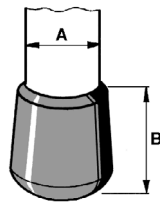


# Rohrkappen

Material: siehe Tabelle (SK-03, SK-07)  
Farbe: schwarz

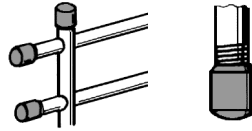

Form 1

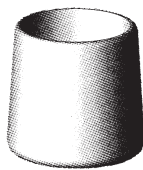

Form 2

Artikel-Nr.	Form	Material	Maße A	B	MOQ Stück
009 0030 220 03	1	LD-PE	3,0	10,0	100
009 0040 220 03	1	LD-PE	4,0	11,0	100
009 0050 220 03	1	LD-PE	5,0	13,0	100
009 0060 220 03	1	LD-PE	6,0	13,0	100
009 0080 220 03	1	LD-PE	8,0	13,0	100
009 0100 220 03	1	LD-PE	10,0	18,0	100
009 0120 220 03	1	LD-PE	12,0	18,0	100
009 0130 220 03	1	LD-PE	13,0	18,0	100
009 0140 220 03	1	LD-PE	14,0	18,0	100
009 0160 220 03	1	LD-PE	16,0	18,0	100
009 0190 220 03	1	LD-PE	19,0	24,0	100
009 0220 220 03	1	LD-PE	22,0	24,0	50
009 0250 220 03	1	LD-PE	25,0	24,0	50
009 0280 220 03	1	LD-PE	28,0	24,0	50
009 0300 699 07	2	PVC	30,0 – 31,0	32,0	50
009 0320 699 07	2	PVC	32,0 – 33,0	32,0	50
009 0340 699 07	2	PVC	34,0	32,0	50
009 0350 699 07	2	PVC	35,0 – 36,0	32,0	50
009 0380 699 07	2	PVC	38,0 – 39,0	32,0	25
009 0400 699 07	2	PVC	40,0 – 41,0	33,0	25
009 0420 699 07	2	PVC	42,0	33,0	25
009 0430 699 07	2	PVC	43,0 – 44,0	33,0	25
009 0450 699 07	2	PVC	45,0 – 46,0	35,0	25
009 0470 699 07	2	PVC	47,0	33,0	25
009 0480 699 07	2	PVC	48,0	35,0	25
009 0490 699 07	2	PVC	49,0 – 51,0	33,0	25
009 0540 699 07	2	PVC	54,0 – 55,0	35,0	25
009 0590 699 07	2	PVC	59,0 – 60,0	38,0	25
009 0630 699 07	2	PVC	63,0 – 64,0	36,0	25
009 0690 699 07	2	PVC	69,0 – 70,0	38,0	25
009 0750 699 07	2	PVC	75,0 – 76,0	38,0	25
009 0900 699 07	2	PVC	90,0	40,0	25
009 1030 699 07	2	PVC	103,0	40,0	25

Preise finden Sie auf unserer Homepage:

[www.pb-elektro.de](http://www.pb-elektro.de)