


**Röhrenlampen T5**

RL

Socket E14

(16 x 54 mm)

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553.....
65-95V		6-10W	<b>00119510</b>	172538
80V	63mA	5W	<b>00118005</b>	172347
	90mA	7W	<b>00118007</b>	172354
	125mA	10W	<b>00118010</b>	172361
	190mA	15W	<b>00118015</b>	172767
110-140V		3-5W	<b>00111405</b>	172545
		5-7W	<b>00111407</b>	172552
		6-10W	<b>00111410</b>	172569
150V	33mA	5W	<b>00111505</b>	172378
220-260V		3-5W	<b>00112603</b>	172576
		4-6W	<b>00112604</b>	172583
		5-7W	<b>00112607</b>	172590
		6-10W	<b>00112610</b>	172606
	stossfest	6-10W	<b>00112610S</b>	172675
		10-15W	<b>00112615</b>	172613
260V stossfest	30mA	7W	<b>00112697</b>	172408
380V	30mA	10W	<b>00113810</b>	172415
<b>Lampenzieher T5</b>			<b>01909009</b>	

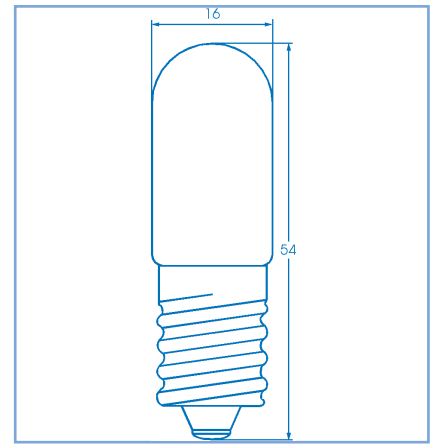


**Röhrenlampen T5**

RL

Socket BA15d

(16 x 54 mm)

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553.....
6V	500mA	3W	<b>00120603</b>	173207
	660mA	4W	<b>00120604</b>	173009
	850mA	5W	<b>00120605</b>	173016
	1,2A	7W	<b>00120607</b>	173023
	2,5A	15W	<b>00120615</b>	173221
12V	250mA	3W	<b>00121203</b>	173238
	330mA	4W	<b>00121204</b>	173030
	420mA	5W	<b>00121205</b>	173047
	850mA	10W	<b>00121210</b>	173054
	1,25A	15W	<b>00121215</b>	173245
24V	80mA	2W	<b>00122402</b>	173061
	125mA	3W	<b>00122403</b>	173252
	160mA	4W	<b>00122404</b>	173078
	200mA	5W	<b>00122405</b>	173085
	300mA	7W	<b>00122407</b>	173092
	420mA	10W	<b>00122442</b>	173269
	625mA	15W	<b>00122415</b>	173108
24-30V		6-10W	<b>00122410</b>	173504
<b>Lampenzieher T5</b>			<b>01909009</b>	

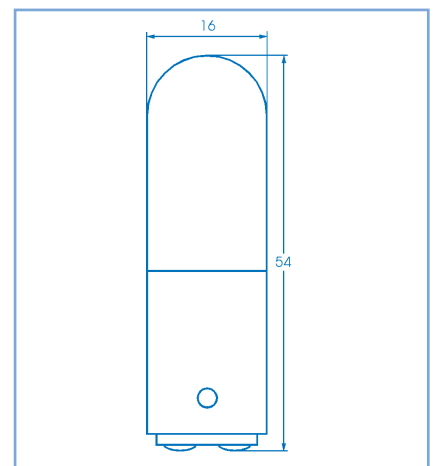

Röhrenlampen

Abweichende Spannungen und Leistungen auf Anfrage lieferbar (VPE 100 Stück) !