


## Tropfenlampen

TR 45

Socket E14

(45 x 70 mm)

TR-illu

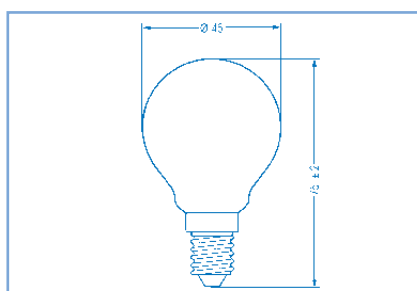

Spannung	Leistung	Ausf.	Artikel-Nr.	EAN 4021553....
24V	15W	matt	<b>00782415</b>	282213
	25W	matt	<b>00782211</b>	282008
	40W	matt	<b>00782411</b>	282282
42V	25W	matt, stossfest	<b>00783211</b>	282022
	40W	matt, stossfest	<b>00783411</b>	282039
65V	15W	matt, stossfest	<b>00784111</b>	282046
130V	15W	klar, stossfest	<b>00786310</b>	282237
		klar	<b>00786210</b>	282107
	25W	matt	<b>00786211</b>	282114
	40W	matt	<b>00786411</b>	282121
	60W	matt	<b>00781360</b>	282251
235V	8W	klar, stossfest	<b>00782318</b>	282299
	8W	matt, stossfest	<b>00782308</b>	282268
	15W	klar, stossfest	<b>00781510</b>	282763
	15W	matt, stossfest	<b>00781511</b>	282770
	15W	opal	<b>00782315OP</b>	282534
	15W	rot, stossfest	<b>007815RO</b>	282602
	15W	gelb, stossfest	<b>007815GE</b>	282619
	15W	grün, stossfest	<b>007815GR</b>	282626
	15W	blau, stossfest	<b>007815BL</b>	282633
	15W	orange, stossfest	<b>007815OR</b>	282640
	25W	klar, stossfest	<b>00788210</b>	282138
	25W	matt, stossfest	<b>00788212</b>	282787
	25W	opal	<b>00782325OP</b>	282541
	25W	rot, stossfest	<b>007825RO</b>	282657
	25W	gelb, stossfest	<b>007825GE</b>	282664
	25W	grün, stossfest	<b>007825GR</b>	282671
	25W	blau, stossfest	<b>007825BL</b>	282688
	25W	orange, stossfest	<b>007825OR</b>	282695
	40W	opal	<b>00782340OP</b>	282558
	40W	klar	<b>00788410</b>	282145
40W	matt	<b>00788411</b>	282152	
60W	matt	<b>00788611</b>	282169	
<b>longlife</b>				
260V	25W		<b>00789211</b>	282183
	40W	matt, stossfest	<b>00789411</b>	282190



Industrielampe!  
Nicht für die Beleuchtung  
im Privathaushalt geeignet!

Abweichende Spannungen und Leistungen auf Anfrage lieferbar (VPE 100 Stück)