


Birnenlampen

BL

Socket E14

(22 x 48 mm)

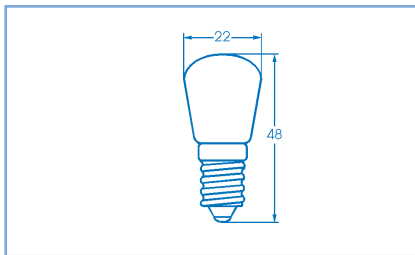

Industrielampe!
Nicht für die Beleuchtung
im Privathaushalt geeignet!


Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553....
12V	416mA	5W	00941205	242421
	833mA	10W	00941210	242438
	1,25A	15W	00941215	252445
	2,08A	25W	00941225	242452
24V	125mA	3W	00942403	242469
	208mA	5W	00942405	242476
	416mA	10W	00942410	242483
	625mA	15W	00942415	242490
	1,04A	25W	00942425	242506
42V	119mA	5W	00944205	252513
42-48V		15W	00944815	242520
60V	250mA	15W	00946015	242551
80V	88mA	7W	00948007	242575
130V	38mA	5W	00941305	242582
	77mA	10W	00941310	242599
	115mA	15W	00941315	242605
220V	45mA	10W	00942210	242612
235V		15W	00892215	302003
220-260V		5-7W	00942607	252629
		6-10W	00942610	252636
		10-15W	00942615	252643

Birnenlampen

BL

Socket BA15d

(22 x 48 mm)

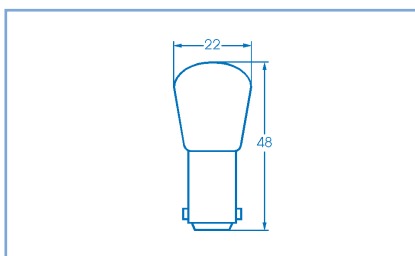

Industrielampe!
Nicht für die Beleuchtung
im Privathaushalt geeignet!

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553....
12V	416mA	5W	00951205	253091
	833mA	10W	00951210	253107
	1,25A	15W	00951215	253114
	2,08A	25W	00951225	253121
24V	208mA	5W	00952405	253138
	292mA	7W	00952407	253145
	416mA	10W	00952410	253152
	625mA	15W	00952415	253169
	1,04A	25W	00952425	253176
50V	200mA	10W	00955010	253190
130V	38mA	5W	00951305	253213
	77mA	10W	00951310	253220
	115mA	15W	00951315	253237
220-260V		5-7W	00952607	253244
		6-10W	00952610	253251
		10-15W	00952615	253268