


Contract Art. Nr. 581445

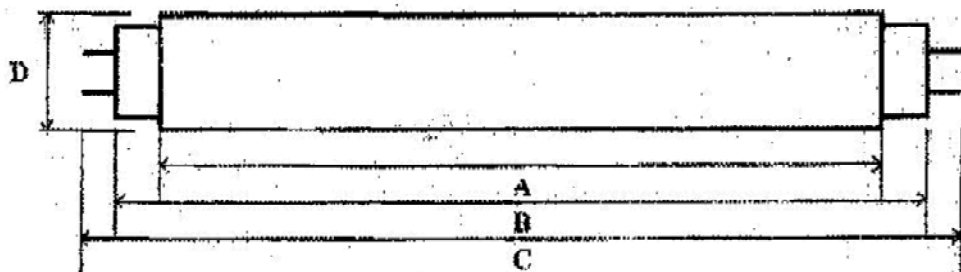


FT008BLB

PRODUCT:	FLUORESCENT TUBE 8W BLB		
LAMP BASE:	G5	LENGTH (A):	288.3MM
RATED VOLTAGE:	56V (64V (max.); 48V (min.))	LENGTH (B max.):	295.4MM
RATED CURRENT:	0.145A	LENGTH (B min.):	293MM
WATTAGE:	8W	LENGTH (C):	302.5MM
AVERAGE LIFE:	> 3,000HOURS	DIAMETER (D):	16MM
		DATE:	29 JUNE, 2004

FLACKERKERZEN UND E-27 SCHWARZLICHTLAMPEN

Artikel Nr.	Bezeichnung	Watt	Abmessungen		Licht- farbe	Sockel	Versandeinheit	
			A (mm)	B (mm)			Inner- karton	Um- karton
37100	Flackerkerze	3	32	102	-	E-14	25	500
37200	A19	75	60	110	UVA	E-27	↓	100
	R25	↓	80	112	↓	↓	↓	↓

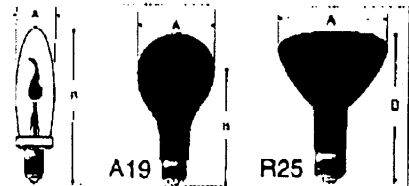

MINIATUR LEUCHSTOFFRÖHREN

„Schwarzlicht“

*Halte, sowie
Starter haben wir auch!*

Artikel Nr.	Bezeichnung	Watt	Abmessungen		Licht- strom (lm)	Licht- farbe	Sockel	Versandeinheit	
			A (mm)	B (mm)				Inner- Karton	Um- karton
39313	F4T5/BLB	4	16	136	-	UVA	G5	10	500
39314	F6T5/BLB	6	↓	212	-	↓	↓	↓	↓
39326	F6T5/WW	↓	↓	↓	200	2700K	↓	↓	↓
39327	F8T5/WW	8	↓	288	280	↓	↓	↓	↓
39328	F13T5/WW	13	↓	517	580	↓	↓	50	200
39315	F8T5/CW	8	↓	288	430	4000K	↓	10	500
39316	F13T5/CW	13	↓	517	930	↓	↓	50	200
39317	F4T5/D	4	↓	136	110	6000K	↓	10	500
39318	F6T5/D	6	↓	212	220	↓	↓	↓	↓
39319	F8T5/D	8	↓	288	310	↓	↓	↓	↓
39325	F13T5/D	13	↓	517	680	↓	↓	50	200

