

**Subminiatur - Glühlampen - BI-PIN**

T1

(3,17 x 9,5 mm)

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...
2,5V	200mA	0,5W	<b>21012200</b>	368399
5V	60mA	0,3W	<b>21010560</b>	369501
	115mA	0,58W	<b>21015115</b>	368405
12V	60mA	0,72W	<b>21011260</b>	369525
14V	65mA	0,9W	<b>21011465</b>	368412
28V	24mA	0,67W	<b>21012824</b>	369532
	40mA	1,12W	<b>21012840</b>	368429



Bild 1

(Stiftsockelabstand 1,27 mm)

**Subminiatur - Glühlampen - BI-PIN**

T1

(3,17 x 9,5 mm)

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...
5V	60mA	0,3W	<b>21020560</b>	369235
	115mA	0,58W	<b>21025115</b>	369204
6V	115mA	0,69W	<b>21026115</b>	369792
12V	60mA	0,72W	<b>21021260</b>	369211
18V	26mA	0,47W	<b>21021826</b>	369259
24V	20mA	0,48W	<b>21022420</b>	369242
28V	24mA	0,67W	<b>21022824</b>	369228
36V	20mA	0,72W	<b>21023620</b>	360065



Bild 2

(Stiftsockelabstand 2,54 mm)

**Subminiatur - Glühlampen - BI-PIN**

T1¼

(4,12 x 14 mm)

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...
6V	60mA	0,36W	<b>21420660</b>	369341
	80mA	0,48W	<b>21420680</b>	360010
12V	40mA	0,48W	<b>21421240</b>	369327
	50mA	0,6W	<b>21421250</b>	368436
14V	80mA	1,12W	<b>21421480</b>	368443
24V	35mA	0,84W	<b>21422435</b>	369303
28V	24mA	0,67W	<b>21422824</b>	369334
	40mA	1,12W	<b>21422840</b>	369310
36V	20mA	0,72W	<b>21423620</b>	368450



Bild 3

(Stiftsockelabstand 2,54 mm)

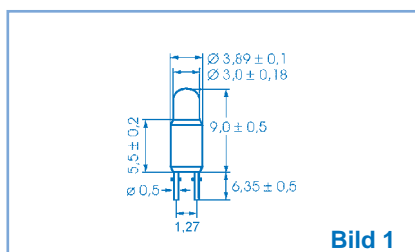


Bild 1

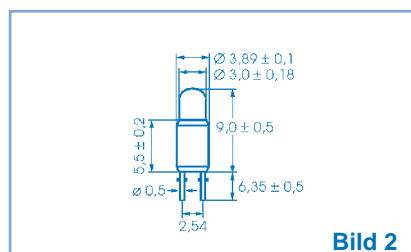


Bild 2

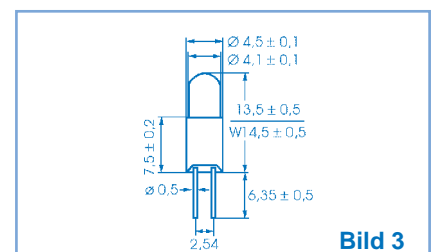


Bild 3

Abweichende Spannungen und Leistungen auf Anfrage lieferbar (VPE 100 Stück)!