

Subminiatur - Glühlampen - BI-PIN

T1

(3,17 x 9,5 mm)

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...
2,5V	200mA	0,5W	21012200	368399
5V	60mA	0,3W	21010560	369501
	115mA	0,58W	21015115	368405
12V	60mA	0,72W	21011260	369525
14V	65mA	0,9W	21011465	368412
28V	24mA	0,67W	21012824	369532
	40mA	1,12W	21012840	368429



Bild 1

(Stiftsockelabstand 1,27 mm)

Subminiatur - Glühlampen - BI-PIN

T1

(3,17 x 9,5 mm)

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...
5V	60mA	0,3W	21020560	369235
	115mA	0,58W	21025115	369204
6V	115mA	0,69W	21026115	369792
12V	60mA	0,72W	21021260	369211
18V	26mA	0,47W	21021826	369259
24V	20mA	0,48W	21022420	369242
28V	24mA	0,67W	21022824	369228
36V	20mA	0,72W	21023620	360065



Bild 2

(Stiftsockelabstand 2,54 mm)

Subminiatur

Subminiatur - Glühlampen - BI-PIN

T1¼

(4,12 x 14 mm)

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...
6V	60mA	0,36W	21420660	369341
	80mA	0,48W	21420680	360010
12V	40mA	0,48W	21421240	369327
	50mA	0,6W	21421250	368436
14V	80mA	1,12W	21421480	368443
24V	35mA	0,84W	21422435	369303
28V	24mA	0,67W	21422824	369334
	40mA	1,12W	21422840	369310
36V	20mA	0,72W	21423620	368450



Bild 3

(Stiftsockelabstand 2,54 mm)

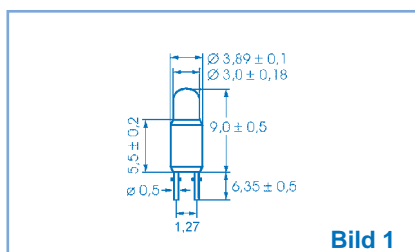


Bild 1

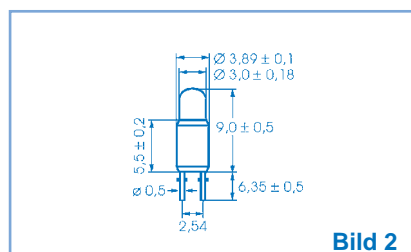


Bild 2

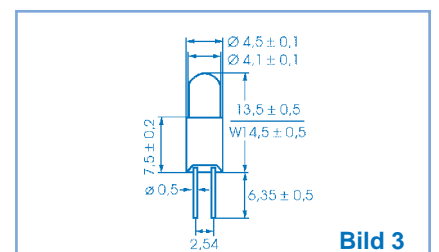


Bild 3

Abweichende Spannungen und Leistungen auf Anfrage lieferbar (VPE 100 Stück)!