

Taschenlampenbirnen

Kugel


Socket E10

(11,5 x 24 mm)

| Spannung | Strom | | Artikel-Nr. | EAN 4021553.... |
|--------------------------------|-------|------|-----------------|--------------------|
| 1,2V | 0,15A | | 00641215 | 410760 |
| 1,5V | 0,2A | | 00641520 | 410777 |
| 2,2V | 0,2A | | 00642220 | 410203 |
| 2,5V | 0,1A | | 00642510 | 410784 |
| | 0,2A | | 00642520 | 410210 |
| | 0,3A | | 00642530 | 410227 |
| 3,5V | 0,2A | | 00643520 | 410234 |
| | 0,3A | | 00643530 | 410326 |
| | 0,2A | rot | 00643521 | 410241 |
| | 0,2A | gelb | 00643522 | 410258 |
| | 0,2A | grün | 00643523 | 410265 |
| 3,8V | 0,07A | | 00643807 | 410289 |
| | 0,3A | | 00643830 | 410296 |
| 4V | 0,5A | | 00644055 | 410319 |
| 4,5V | 0,1A | | 00644510 | 410791 |
| 4,8V | 0,3A | | 00644830 | 410333 |
| 6,0V | 0,1A | 0,6W | 00660606 | 410401 |
| für Fahrradschlusslicht | | | | |
| 6,2V | 0,3A | | 00646230 | 410302 |
| 8V | 0,05A | | 00640850 | 410364 |
| 14V | 0,2A | | 00641402 | 410357 |



VPE 10 Stück

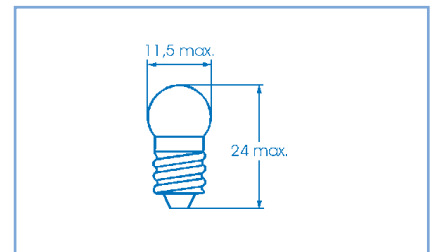

Taschenlampenbirnen

Olive


Socket P13,5s

(11,5 x 30 mm)

| Spannung | Strom | | Artikel-Nr. | EAN 4021553.... |
|----------|-------|--------|-----------------|--------------------|
| 1,5V | 0,07A | | 00651507 | 419190 |
| 2,4V | 0,5A | (PR2) | 00652450 | 419107 |
| 2,5V | 0,2A | | 00652520 | 419114 |
| | 0,3A | (PR6) | 00652530 | 419121 |
| 3,6V | 0,5A | (PR3) | 00653650 | 419138 |
| 3,8V | 0,3A | (PR7) | 00653830 | 419145 |
| 4,8V | 0,5A | | 00654850 | 419152 |
| 6,0V | 0,5A | (PR12) | 00656050 | 419169 |
| 7,2V | 0,5A | (PR18) | 00657250 | 419176 |
| 9,0V | 0,5A | (PR20) | 00659050 | 419183 |
| 12V | 0,25A | | 00651225 | 524729 |



VPE 10 Stück

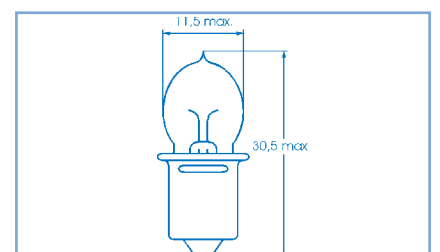

TALA-Birnen