

Art.-Nr.	A	B	C	D	E	F
603 136	46	28	44	54	60	45
603 136-1	46	28	47	60	60	45
603 136-2	46	28	56	70	70	45
603 136-3	46	28	45	55	55	51
603 136-4	46	28	60	75	75	51
603 136-5	46	28	52	65	65	51
603 156	48	28	56	70	70	56
603 156-1	48	28	60	75	75	56
603 156-2	48	28	52	65	72	56
603 236	61	29	56	70	70	56
603 236-1	46	28	60	75	75	51
603 256	60	29	56	70	70	56
603 256-1	60	29	60	75	75	56

IP 44 spritzwassergeschützt

CEE - ANBAUDOSE

GERADE




Zwischenflansch
für Kabelkanal

auf Anfrage



mit Flanschdichtung

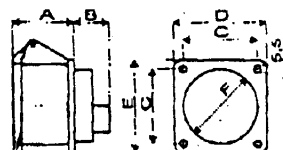

Artikel-Nr.	Nennstrom Ampere	Polzahl	Nennspannung Volt			Waren- gruppe	Verpackungs- einheit	Umkarton	Netto-Preis per Stück
603 136	16	3-polig	230	6 h	blau	4122	1	10	
603 136-1	16	3-polig	230	6 h	blau	4122	1	10	
603 136-2	16	3-polig	230	6 h	blau	4122	1	10	
603 136-3	16	3-polig	230	6 h	blau	4122	1	10	
603 136-4	16	3-polig	230	6 h	blau	4122	1	10	
603 136-5	16	3-polig	230	6 h	blau	4122	1	10	
603 156	16	5-polig	400	6 h	rot	4122	1	10	
603 156-1	16	5-polig	400	6 h	rot	4122	1	10	
603 156-2	16	5-polig	400	6 h	rot	4122	1	10	
603 236	32	3-polig	230	6 h	blau	4122	1	10	
603 236-1	32	3-polig	230	6 h	blau	4122	1	10	
603 256	32	5-polig	400	6 h	rot	4122	1	10	
603 256-1	32	5-polig	400	6 h	rot	4122	1	10	

CEE - ANBAUDOSE


SCHRÄG

Art.-Nr.	A	B	C	D	E	F	G	H
604 136	41	43	50	70	85	51	65	61
604 156	44	45	60	80	95	65	73	76
604 236	50	51	60	80	95	65	73	75
604 256	52	50	60	80	95	70	73	80

IP 44 spritzwassergeschützt



mit Flanschdichtung

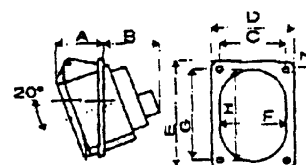

Weitere Ausführungen
auf Anfrage

Artikel-Nr.	Nennstrom Ampere	Polzahl	Nennspannung Volt			Waren- gruppe	Verpackungs- einheit	Umkarton	Netto-Preis per Stück
604 136	16	3-polig	230	6 h	blau	4122	1	10	
604 156	16	5-polig	400	6 h	rot	4122	1	10	
604 236	32	3-polig	230	6 h	blau	4122	1	10	
604 256	32	5-polig	400	6 h	rot	4122	1	10	