

## Stromwandler für PEL 102 / PEL 103


**MiniFlex MA193** –  $\varnothing$  70 mm - (0,1 ... 10 000 AAC)

**AmpFlex A 193** – 450 mm -  $\varnothing$  140 mm - (0,1 ... 10 000 AAC)


**AmpFlex A 193** – 800 mm -  $\varnothing$  250 mm - (0,1 ... 10 000 AAC)

Zangen **MN93A** -  $\varnothing$  20 mm - (0,005...5A; 0,1...120 AAC)


Zangen **MN93** -  $\varnothing$  20 mm - (0,5...240 AAC)

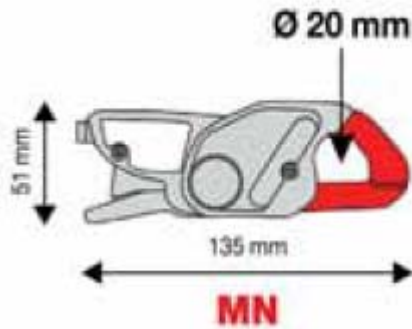

Zangen **C193** -  $\varnothing$  52 mm - (3...1200 AAC)

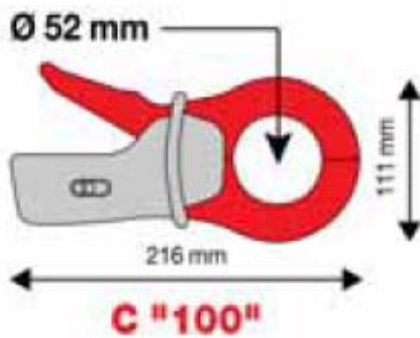

Zangen **PAC 93** -  $\varnothing$  30 mm - (10...1000 AAC bzw. 1400 ADC)

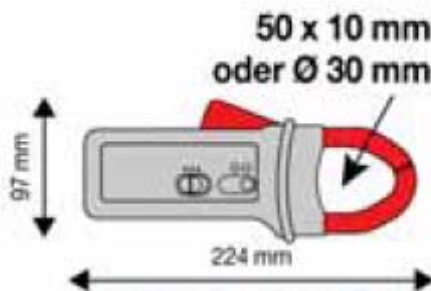

**Stromwandler für  
C.A 8220, C.A 8230, C.A 8332B, C.A 8334B, C.A 8335**


**MiniFlex MA193** –  $\varnothing$  70 mm - (30...6500 AAC)

**AmpFlex A 193** – 450 mm -  $\varnothing$  140 mm - (30...6500 AAC)


**AmpFlex A 193** – 800 mm -  $\varnothing$  250 mm - (30...6500 AAC)

Zangen **MN93A** -  $\varnothing$  20 mm - (0,005...5...120 AAC)

Zangen **MN93** -  $\varnothing$  20 mm - (2...240 AAC)

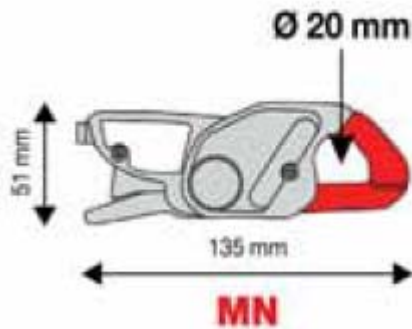

Zangen **C193** -  $\varnothing$  52 mm - (3...1200 AAC)

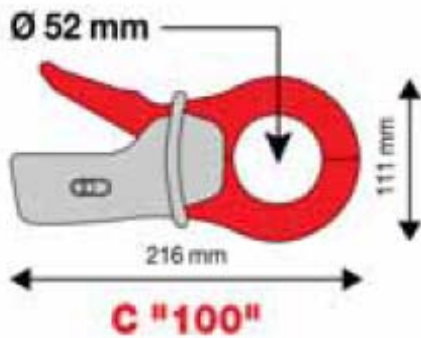

Zangen **PAC 93** -  $\varnothing$  30 mm - (10...1000 AAC bzw. 1400 ADC)

