

3-polig, IP 66 / 67

Gehäuseeinbau mit Türkupplung



3-polig




Dauerstrom (I ₀ /I _{th})	Schaltleistung AC-23B (A)	Frontschild	Artikelnummer	ab Lager lieferbar
3-polig 3 x 400 V				
20 A	5,5 kW	64 x 64	KG10B T203/09 VE	
25 A	7,5 kW	64 x 64	KG20B T203/09 VE	
32 A	11 kW	64 x 64	KG32B T203/09 VE	●
40 A	15 kW	64 x 64	KG41B T203/09 VE	●
63 A	22 kW	64 x 64	KG64B T203/09 VE	●
80 A	30 kW	64 x 64	KG80 T203/09 VE	●
100 A	37 kW	64 x 64	KG100 T203/09 VE	●
125 A	45 kW	88 x 88	KG125 T203/09 VE	●
160 A	55 kW	88 x 88	KG160 T203/09 VE	●

Dauerstrom (I ₀ /I _{th})	Schaltleistung AC-23B (A)	Frontschild	Artikelnummer	ab Lager lieferbar
3-polig 3 x 400 V				
20 A	5,5 kW	64 x 64	KG10B T103/09 VE	
25 A	7,5 kW	64 x 64	KG20B T103/09 VE	
32 A	11 kW	64 x 64	KG32B T103/09 VE	
40 A	15 kW	64 x 64	KG41B T103/09 VE	●
63 A	22 kW	64 x 64	KG64B T103/09 VE	●
80 A	30 kW	64 x 64	KG80 T103/09 VE	
100 A	37 kW	64 x 64	KG100 T103/09 VE	●
125 A	45 kW	88 x 88	KG125 T103/09 VE	
160 A	55 kW	88 x 88	KG160 T103/09 VE	

Lochbild Frontschild


bis KG100

 KG125-KG160




Lochbild Boden (Befestigung auf Normschiene bis KG100)

KG10B KG20B-KG100 KG125-KG160

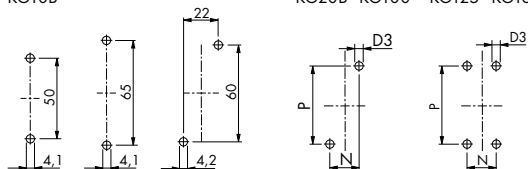


Maximale Anzahl Vorhängeschlösser		
Frontschild	Bügel-Ø	Anzahl Schlösser
64 x 64	9	3
88 x 88	10	3

KG10B - KG64B

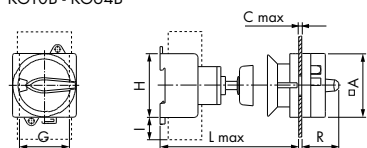

KG80-KG160

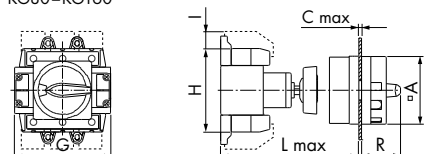

	N	P	D3
KG20B, KG32B	22	60	4,1
KG41B, KG64B	25	70	4,1
KG80, KG100	25	90	5,2
KG125, KG160	36	120	6,4

	A	C	G	H	I	L	R
KG10B	64	4	48	50		190	40,1
KG20B, KG32B	64	4	42	54		190	40,1
KG41B, KG64B	64	4	50	64		190 ¹	40,1
KG80, KG100	64	4	70	80	26	380 ²	40,1
KG125, KG160	88	5,5	112	108	22,2	450	49,3

¹ KG64B = 330 | ² KG100 = 450

Informationen zu KG-Schaltern mit Bolzenanschlüssen finden Sie auf Seite 37.

