

3-polig, IP 66

Schaltschrankeinbau mit Türkupplung



 
Entriegelungsstück zur Aufhebung der Türverriegelung siehe Seite 38.



Dauerstrom (I _N /I _{th})	Schaltleistung AC-23B (A)	Frontschild	Artikelnummer	ab Lager lieferbar
3-polig 3 x 400 V				
40 A	15 kW	88 x 88	KG41B T203/12 VE	●
63 A	22 kW	88 x 88	KG64B T203/12 VE	●
80 A	30 kW	88 x 88	KG80 T203/12 VE	●
100 A	37 kW	88 x 88	KG100 T203/12 VE	●
125 A	45 kW	88 x 88	KG125 T203/12 VE	●
160 A	55 kW	88 x 88	KG160 T203/12 VE	●
200 A	75 kW	88 x 88	KG210 T203/13 VE	●
250 A	90 kW	88 x 88	KG250 T203/13 VE	●
315 A	110 kW	88 x 88	KG315 T203/13 VE	●
315 A	132 kW	88 x 88	C316 T203/13 VE	●


Dauerstrom (I _N /I _{th})	Schaltleistung AC-23B (A)	Frontschild	Artikelnummer	ab Lager lieferbar
3-polig 3 x 400 V				
40 A	15 kW	88 x 88	KG41B T103/12 VE	●
63 A	22 kW	88 x 88	KG64B T103/12 VE	●
80 A	30 kW	88 x 88	KG80 T103/12 VE	●
100 A	37 kW	88 x 88	KG100 T103/12 VE	●
125 A	45 kW	88 x 88	KG125 T103/12 VE	●
160 A	55 kW	88 x 88	KG160 T103/12 VE	●
200 A	75 kW	88 x 88	KG210 T103/13 VE	●
250 A	90 kW	88 x 88	KG250 T103/13 VE	●
315 A	110 kW	88 x 88	KG315 T103/13 VE	●
315 A	132 kW	88 x 88	C316 T103/13 VE	●

Lochbild Frontschild




Lochbild Boden (Befestigung auf Normschiene bis KG100)


KG41B-KG100

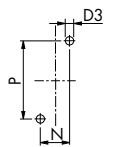


KG125-C316

 

KG

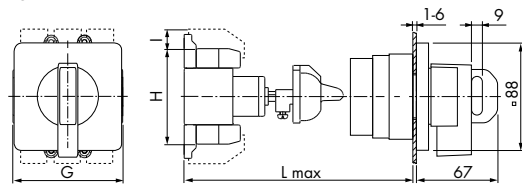

C316

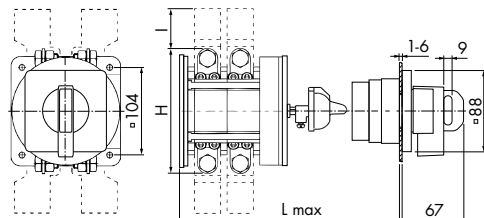

Frontschild	Bügel-Ø	Anzahl Schösser
48 x 48	7	3
	5	4
	8	3
64 x 64	5	4
	9	4
88 x 88	9	4
130 x 130	9	4

	N	P	D3
KG41B, KG64B	25	70	4,1
KG80, KG100	25	90	5,2
KG125, KG160	36	120	6,4
KG210-KG315	44	142	6,4
C316	104	104	7

	G	H	I	L
KG41B	50	64		190
KG64B	50	64		330
KG80	70	80		380
KG100	70	80	26	450
KG125, KG160	112	108	26	450
KG210-KG315	145	126	25	550
C316	128	150	46	550

Informationen zu KG-Schaltern mit Bolzenanschlüssen finden Sie auf Seite 37.



3-polig

