

Taschenlampenbirnen

Kugel


Socket E10

(11,5 x 24 mm)

Spannung	Strom	Artikel-Nr.	EAN 4021553....	
1,2V	0,15A	00641215	410760	
1,5V	0,2A	00641520	410777	
2,2V	0,2A	00642220	410203	
2,5V	0,1A	00642510	410784	
	0,2A	00642520	410210	
	0,3A	00642530	410227	
3,5V	0,2A	00643520	410234	
	0,3A	00643530	410326	
	0,2A	rot	00643521	410241
	0,2A	gelb	00643522	410258
	0,2A	grün	00643523	410265
3,8V	0,2A	blau	00643524	410272
	0,07A	00643807	410289	
4V	0,3A	00643830	410296	
4,5V	0,5A	00644055	410319	
4,5V	0,1A	00644510	410791	
4,8V	0,3A	00644830	410333	
6,0V	0,1A	0,6W	00660606	410401
für Fahrradschlusslicht				
6,2V	0,3A	00646230	410302	
8V	0,05A	00640850	410364	
14V	0,2A	00641402	410357	



VPE 10 Stück

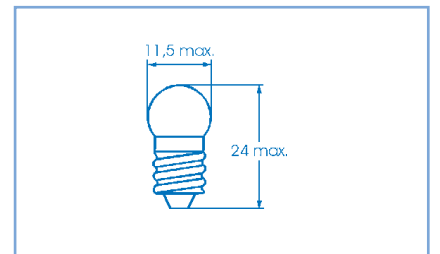

Taschenlampenbirnen

Olive

Socket P13,5s

(11,5 x 30 mm)

Spannung	Strom	Artikel-Nr.	EAN 4021553....
1,5V	0,07A	00651507	419190
2,4V	0,5A (PR2)	00652450	419107
2,5V	0,2A	00652520	419114
	0,3A (PR6)	00652530	419121
3,6V	0,5A (PR3)	00653650	419138
3,8V	0,3A (PR7)	00653830	419145
4,8V	0,5A	00654850	419152
6,0V	0,5A (PR12)	00656050	419169
7,2V	0,5A (PR18)	00657250	419176
9,0V	0,5A (PR20)	00659050	419183
12V	0,25A	00651225	524729



VPE 10 Stück

