


Subminiatur - Glühlampen - Wire Terminal

T^{3/4}

(2,5 x 6,5 mm)

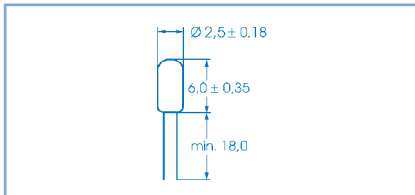



Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...
4V	115mA	0,5W	21090415	368092
5V	60mA	0,3W	21090560	369808
	80mA	0,4W	21090580	369815
6V	115mA	0,6W	21090515	360003
	25mA	0,15W	21090625	368108
12V	25mA	0,3W	21091225	368115
	50mA	0,6W	21091250	369822
24V	20mA	0,48W	21092420	369839

Subminiatur - Glühlampen - Wire Terminal

T1

(3,2 x 6,5 mm)

Subminiatur

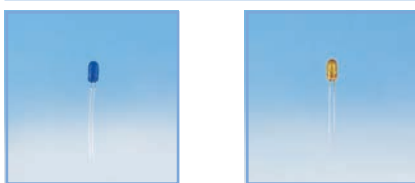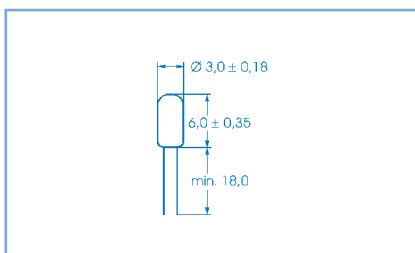

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...	
1,5V	75mA	0,11W	21109157	369846	
2,5V	65mA	0,16W	21109255	368047	
3V	12mA	0,04W	21109312	360034	
	40mA	0,12W	21109340	368306	
5V	115mA	0,35W	21109315	368122	
	21mA	0,11W	21109521	369853	
	30mA	0,15W	21109530	369860	
	40mA	0,2W	21109540	368313	
	60mA	0,3W	21109560	369877	
6V	115mA	0,6W	21109515	369884	
	125mA	0,63W	21109525	369891	
	25mA	0,15W	21109615	368139	
	40mA	0,24W	21109640	368320	
	50mA	0,25W	21109650	369907	
	60mA	0,36W	21109660	369914	
8V	70mA	0,42W	21109670	369921	
	115mA	0,7W	21109615	360041	
	80mA	0,64W	21109880	368337	
	12V	30mA	0,36W	21109123	369938
		40mA	0,48W	21101240	369945
40mA		0,48W	2110124B	368009	
40mA		0,48W	2110124G	368016	
40mA		0,48W	2110124R	368023	
40mA		0,48W	2110124Y	368030	
blau grün rot gelb	40mA	0,48W	21109124	368344	
	50mA	0,6W	21109125	369952	
	60mA	0,72W	21109126	369969	
14V	40mA	0,56W	21109144	368351	
	80mA	1,12W	21109148	369976	
18V	21mA	0,38W	21109181	368146	
	26mA	0,47W	21109182	369983	
24V	20mA	0,48W	21109242	369990	
28V	24mA	0,67W	21109282	369099	
36V	20mA	0,72W	21109362	368153	