

**Taschenlampenbirnen**

**Kugel**


**Socket E10**

**(11,5 x 24 mm)**

Spannung	Strom	Artikel-Nr.	EAN 4021553....
1,2V	0,15A	<b>00641215</b>	410760
1,5V	0,2A	<b>00641520</b>	410777
2,2V	0,2A	<b>00642220</b>	410203
2,5V	0,1A	<b>00642510</b>	410784
	0,2A	<b>00642520</b>	410210
	0,3A	<b>00642530</b>	410227
3,5V	0,2A	<b>00643520</b>	410234
	0,3A	<b>00643530</b>	410326
	0,2A	rot <b>00643521</b>	410241
	0,2A	gelb <b>00643522</b>	410258
	0,2A	grün <b>00643523</b>	410265
3,8V	0,2A	blau <b>00643524</b>	410272
	0,07A	<b>00643807</b>	410289
4V	0,3A	<b>00643830</b>	410296
4,5V	0,5A	<b>00644055</b>	410319
4,5V	0,1A	<b>00644510</b>	410791
4,8V	0,3A	<b>00644830</b>	410333
6,0V	0,1A	0,6W <b>00660606</b>	410401
<b>für Fahrradschlusslicht</b>			
6,2V	0,3A	<b>00646230</b>	410302
8V	0,05A	<b>00640850</b>	410364
14V	0,2A	<b>00641402</b>	410357



**VPE 10 Stück**

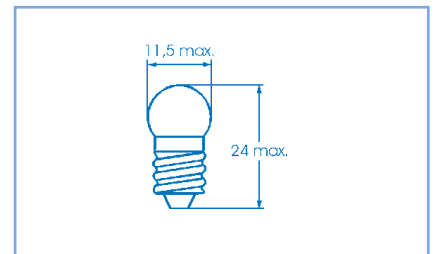

**Taschenlampenbirnen**

**Olive**

**Socket P13,5s**

**(11,5 x 30 mm)**

Spannung	Strom	Artikel-Nr.	EAN 4021553....
1,5V	0,07A	<b>00651507</b>	419190
2,4V	0,5A (PR2)	<b>00652450</b>	419107
2,5V	0,2A	<b>00652520</b>	419114
	0,3A (PR6)	<b>00652530</b>	419121
3,6V	0,5A (PR3)	<b>00653650</b>	419138
3,8V	0,3A (PR7)	<b>00653830</b>	419145
4,8V	0,5A	<b>00654850</b>	419152
6,0V	0,5A (PR12)	<b>00656050</b>	419169
7,2V	0,5A (PR18)	<b>00657250</b>	419176
9,0V	0,5A (PR20)	<b>00659050</b>	419183
12V	0,25A	<b>00651225</b>	524729



**VPE 10 Stück**

