


Kleinröhrenlampen T3^{1/4}

KRL 28

Socket E10

(10 x 28 mm)

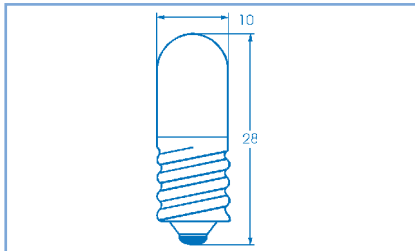

Die fettgedruckten Typen kommen in Leuchtmeldern und Leuchttastern aller namhaften Hersteller zum Einsatz

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553....
6V	50mA	0,3W	00210650	100647
	75mA	0,45W	00210675	100654
	100mA	0,6W	00210610	100661
	180mA	1,1W	00210618	100012
	300mA	1,8W	00210630	100982
	333mA	2,0W	00210602	100029
	500mA	3,0W	00210603	100036
	830mA	5,0W	00210605	100043
	1000mA	6,0W	00210606	100050
6,3V	320mA	2W	00210632	100999
6-7V		2,0W	00210702	100364
7V	100mA	0,7W	00210710	100852
	300mA	2,1W	00210730	100678
8V	320mA	2,24W	00210722	100937
	100mA	0,8W	00210808	100456
9V	300mA	2,4W	00210830	100685
	450mA	4,0W	00210945	100500
10V	50mA	0,5W	00211050	100692
	100mA	1,0W	00211001	100708
	200mA	2,0W	00211020	100715
12V	50mA	0,6W	00211250	100470
	100mA	1,2W	00211210	100869
	120mA	1,44W	00211212	100067
	165mA	2,0W	00211202	100074
	200mA	2,4W	00211220	100876
	250mA	3,0W	00211203	100081
12-15V	417mA	5,0W	00211205	100098
		2,0W	00211502	100371
14V	80mA	1,12W	00211480	100838
	200mA	2,8W	00211420	090450
15V	50mA	0,75W	00211550	100722
	100mA	1,5W	00211510	100739
	200mA	3,0W	00211520	100746
18V	100mA	1,8W	00211810	100753
	170mA	3W	00211817	090467
24V	20mA	0,5W	00212420	100487
	40mA	1,0W	00212440	100883
	50mA	1,2W	00212450	100104
	60mA	1,5W	00212460	100890
	80mA	2,0W	00212408	100111
	100mA	2,4W	00212410	100524
	125mA	3,0W	00212403	100128
	160mA	4,0W	00212404	100906
24-30V	208mA	5,0W	00212405	100135
		2,0W	00213002	100388
		4,0W	00213014	100395
Lampenzieher T3^{1/4}			01909007	