


**Glassockellampen**

**T5**

**Socket W2x4,6d**

**(5 x 20 mm)**

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...
6V	166mA	1,0W	<b>00560601</b>	375045
	200mA	1,2W	<b>00560612</b>	375076
6-7V	30mA	0,2W	<b>00550630</b>	375007
	80mA	0,5W	<b>00550680</b>	375014
12V	100mA	1,2W	<b>00561212</b>	375083
	100mA	blau	<b>00561212B</b>	375410
	100mA	grün	<b>00561212G</b>	375403
	100mA	rot	<b>00561212R</b>	375397
	100mA	gelb	<b>00561212Y</b>	375427
	166mA	2,0W	<b>00561202</b>	375212
12-15V	30mA	0,4W	<b>00551230</b>	375021
	83mA	1,0W	<b>00561201</b>	375052
14V	80mA	1,1W	<b>00561480</b>	375199
24V	50mA	1,2W	<b>00562412</b>	375090
24-30V	30mA	0,7W	<b>00552430</b>	375038
	40mA	1,0W	<b>00562401</b>	375069
48V	25mA	1,2W	<b>00554825</b>	375175
60V	20mA	1,2W	<b>00556020</b>	375182
<b>Lampenzieher T1½</b>			<b>01909003</b>	

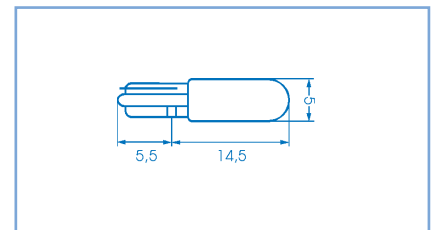


**Glassockellampen**

**T10**

**Socket W2,1x9,5d**

**(10 x 27 mm)**

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...
6,3V	150mA	1,0W	<b>00570615</b>	375366
6-7V	333mA	2,0W	<b>00570602</b>	375106
12V	100mA	1,2W	<b>00571212</b>	375168
	250mA	3,0W	<b>00571203</b>	375144
	420mA	5,0W	<b>00571205</b>	375151
12-15V	166mA	2,0W	<b>00571202</b>	375113
24-30V	83mA	2,0W	<b>00572402</b>	375120
48-60V	33mA	2,0W	<b>00574802</b>	375137
<b>Lampenzieher T3¼</b>			<b>01909007</b>	

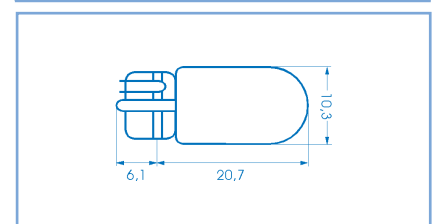

Kleinslampen