


Glassockellampen

T5

Socket W2x4,6d

(5 x 20 mm)

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...
6V	166mA	1,0W	00560601	375045
	200mA	1,2W	00560612	375076
6-7V	30mA	0,2W	00550630	375007
	80mA	0,5W	00550680	375014
12V	100mA	1,2W	00561212	375083
	100mA	blau	00561212B	375410
	100mA	grün	00561212G	375403
	100mA	rot	00561212R	375397
	100mA	gelb	00561212Y	375427
	166mA	2,0W	00561202	375212
12-15V	30mA	0,4W	00551230	375021
	83mA	1,0W	00561201	375052
14V	80mA	1,1W	00561480	375199
24V	50mA	1,2W	00562412	375090
24-30V	30mA	0,7W	00552430	375038
	40mA	1,0W	00562401	375069
48V	25mA	1,2W	00554825	375175
60V	20mA	1,2W	00556020	375182
Lampenzieher T1½			01909003	

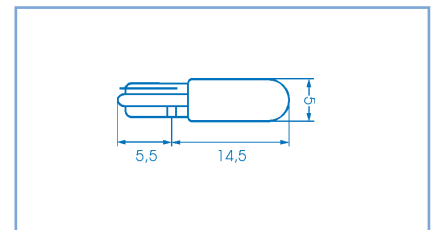


Glassockellampen

T10

Socket W2,1x9,5d

(10 x 27 mm)

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...
6,3V	150mA	1,0W	00570615	375366
6-7V	333mA	2,0W	00570602	375106
12V	100mA	1,2W	00571212	375168
	250mA	3,0W	00571203	375144
	420mA	5,0W	00571205	375151
12-15V	166mA	2,0W	00571202	375113
24-30V	83mA	2,0W	00572402	375120
48-60V	33mA	2,0W	00574802	375137
Lampenzieher T3¼			01909007	

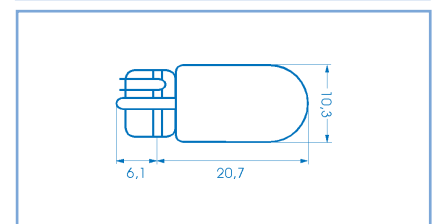

Kleinpampen