


**Röhrenlampen**                      **RL Größe 1**                      **klar**                      **Socket BA15d**                      **(20 x 85 mm)**

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553....
12V	2A	25W	<b>00731215</b>	183053
24V	625mA	15W	<b>00732415</b>	183008
	1A	25W	<b>00732425</b>	183015
42V	600mA	25W	<b>00734225</b>	183039
65V	250mA	15W	<b>00736015</b>	183039
130V	130mA	15W	<b>00731115</b>	183022
235V	64mA	15W	<b>00732215</b>	183046

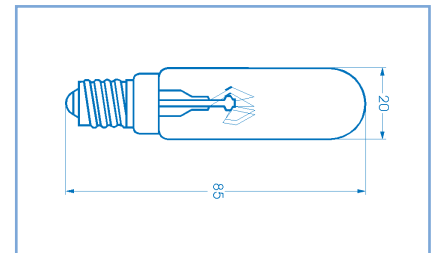

**Röhrenlampen**                      **RL Größe 2**                      **klar**                      **Socket E14**                      **(20 x 115 mm)**

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553....
130V	115mA	15W	<b>00911315</b>	192024
235V	100mA	25W	<b>00918212</b>	192000
	*matt	25W	<b>00918212M</b>	192031
	170mA	40W	<b>00918211</b>	192017



\* Industrielampe

**Röhrenlampen**                      **RL Größe 3**                      **matt / klar**                      **Socket E14**                      **(30 x 90 mm)**

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553....
130V	*matt	25W	<b>00918313</b>	202044
		40W	<b>00918513</b>	202051
240V	klar	25W	<b>00918613</b>	202068
	*matt	25W	<b>00918013</b>	202020
	matt	40W	<b>00918113</b>	202037



\* Industrielampe