


## Signal-Soffittenlampen

Socket S5,5

(6 x 31 mm)

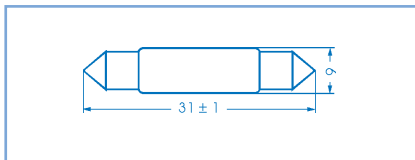


Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...
6V	500mA	3,0W	00310603	398105
12V	100mA	1,2W	00311212	398167
	165mA	2,0W	00311202	398112
	250mA	3,0W	00311203	398129
13,5V	88mA	1,2W	00311312	398174
18V	55mA	1,0W	00311801	398136
	166mA	3,0W	00311803	398181
24V	50mA	1,2W	00312412	398198
	83mA	2,0W	00312402	398921
	125mA	3,0W	00312403	398143
30V	50mA	1,5W	00313015	398938
48V	63mA	3,0W	00314803	398945
60V	50mA	3,0W	00316003	398150

## Signal-Soffittenlampen

Socket S5,5

(6 x 36 mm)

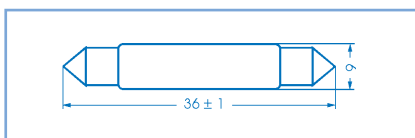


Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...
6V	500mA	3,0W	00320603	398204
12V	100mA	1,2W	00321212	408699
	Grün	1,2W	003212GR	408712
	Rot	1,2W	003212RO	408729
	250mA	3,0W	00321203	398211
15V	80mA	1,2W	00321512	398228
	für Sprechanlagen			
18V	166mA	3,0W	00321803	398273
24V	50mA	1,2W	00322412	398266
	für Sprechanlagen			
	83mA	2,0W	00322402	398280
	125mA	3,0W	00322403	398235
30V	100mA	3,0W	00323003	398242
36V	80mA	3,0W	00323603	398259
48V	63mA	3,0W	00324803	398297

Kleinslampen

## Signal-Soffittenlampen

 Socket S5,5

(6 x 39 mm)



Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...
6V	500mA	3,0W	00330603	398358
12V	250mA	3,0W	00331203	398365
13,5V	90mA	1,2W	00331312	398303
	für Sprechanlagen			
17V	120mA	2,0W	00331702	398334
18V	100mA	1,8W	00331801	398310
	166mA	3,0W	00331803	398341
24V	50mA	1,2W	00332412	398372
	125mA	3,0W	00332403	398389
36V	80mA	3,0W	00333603	398327
48V	63mA	3,0W	00334803	398369