


Signal-Soffittenlampen

Socket S8

(11 x 43 mm)

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...
3,5V	200mA	0,7W	00383507	408279
6V	500mA	3,0W	00380603	408521
	833mA	5,0W	00380605	408538
12V	250mA	3,0W	00381203	408200
	250mA	3,0W	003812G5	409023
	415mA	5,0W	00381205	408217
	415mA	5,0W	003812R5	409030
	833mA	10,0W	00381210	408545
18V	280mA	5,0W	00381805	408460
24V	50mA	1,2W	00382412	408552
	83mA	2,0W	00382402	408569
	125mA	3,0W	00382403	408224
farbig		3,0W	003824(XX)	
	210mA	5,0W	00382405	408231
farbig	210mA	5,0W	003825(XX)	
grün	210mA	5,0W	003824G5	408248
rot	210mA	5,0W	003824R5	408255
30V	420mA	10,0W	00382410	408576
	100mA	3,0W	00383003	408583
42V	165mA	5,0W	00383005	408286
	120mA	5,0W	00384205	408590
48V	63mA	3,0W	00384803	408606
	105mA	5,0W	00384805	408262
60V	50mA	3,0W	00386003	408293
	83mA	5,0W	00386005	408453

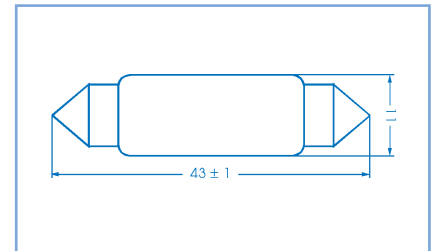


XX= GE - Gelb
RO - Rot
GR - Grün
BL - Blau
OR - Orange

Signal-Soffittenlampen

Socket S8

(15 x 43 mm)

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...
6V	500mA	3,0W	00390603	408309
	830mA	5,0W	00390605	408316
	1,66A	10,0W	00390610	408613
12V	250mA	3,0W	00391203	408446
	415mA	5,0W	00391205	408323
	833mA	10,0W	00391210	408620
	Blau	15,0W	003912BL	418018
24V	125mA	3,0W	00392403	408330
	210mA	5,0W	00392405	408347
	farbig	5,0W	003924(XX)	
30V	290mA	7,0W	00392407	408361
	420mA	10,0W	00392410	408637
	100mA	3,0W	00393003	408378
42V	165mA	5,0W	00393005	408385
	333mA	10,0W	00393010	408644
36V	140mA	5,0W	00393605	408392
48V	70mA	3,0W	00394203	408408
	120mA	5,0W	00394205	408415
48V	105mA	5,0W	00394805	408422
60V	80mA	5,0W	00396005	408439

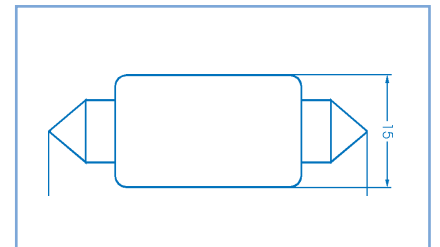

XX= GE - Gelb
RO - Rot
GR - Grün
BL - Blau
OR - Orange